


## Connecting cable with socket

ADOGH040MSS07,5E03

Article no longer available - archive entry

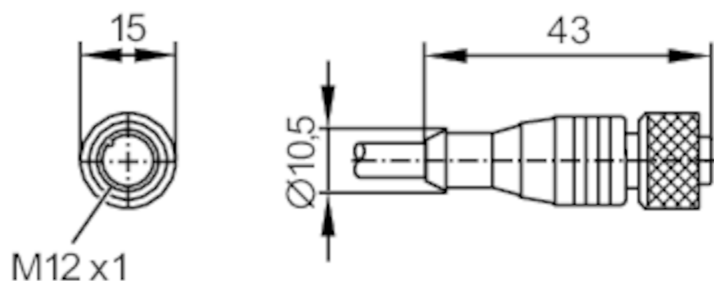

## Electrical data

|                   |     |                     |
|-------------------|-----|---------------------|
| Operating voltage | [V] | < 250 AC / < 300 DC |
|-------------------|-----|---------------------|

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

## Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Dimensions            | [mm] | 15 x 15 x 43         |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |

## Remarks

 
|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

## Electrical connection

Cable: 7.5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

## Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



# E10533



## Connecting cable with socket

ADOGH040MSS07,5E03

### Connection



|      |                |       |
|------|----------------|-------|
| BN = | Core colours : | brown |
| BK = |                | black |
| BU = |                | blue  |