


E10545



Connecting cable with socket

ADOAH042ZDS0015A03

Article no longer available - archive entry

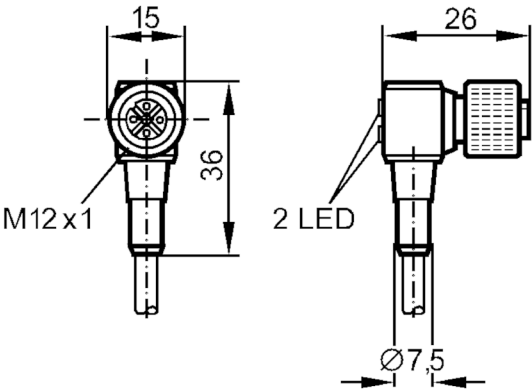

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	36 x 15 x 26
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10545



Connecting cable with socket

ADOAH042ZDS0015A03

Electrical connection


Cable: 15 m, PVC, black, Ø 4.5 mm; 4 x 0.34 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection

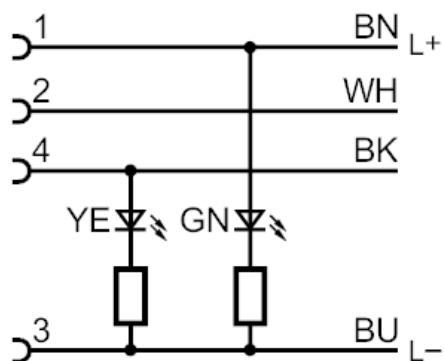

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white