




Connection cable

VDOGG030--S01,5A03STGH030MSS

Article no longer available - archive entry

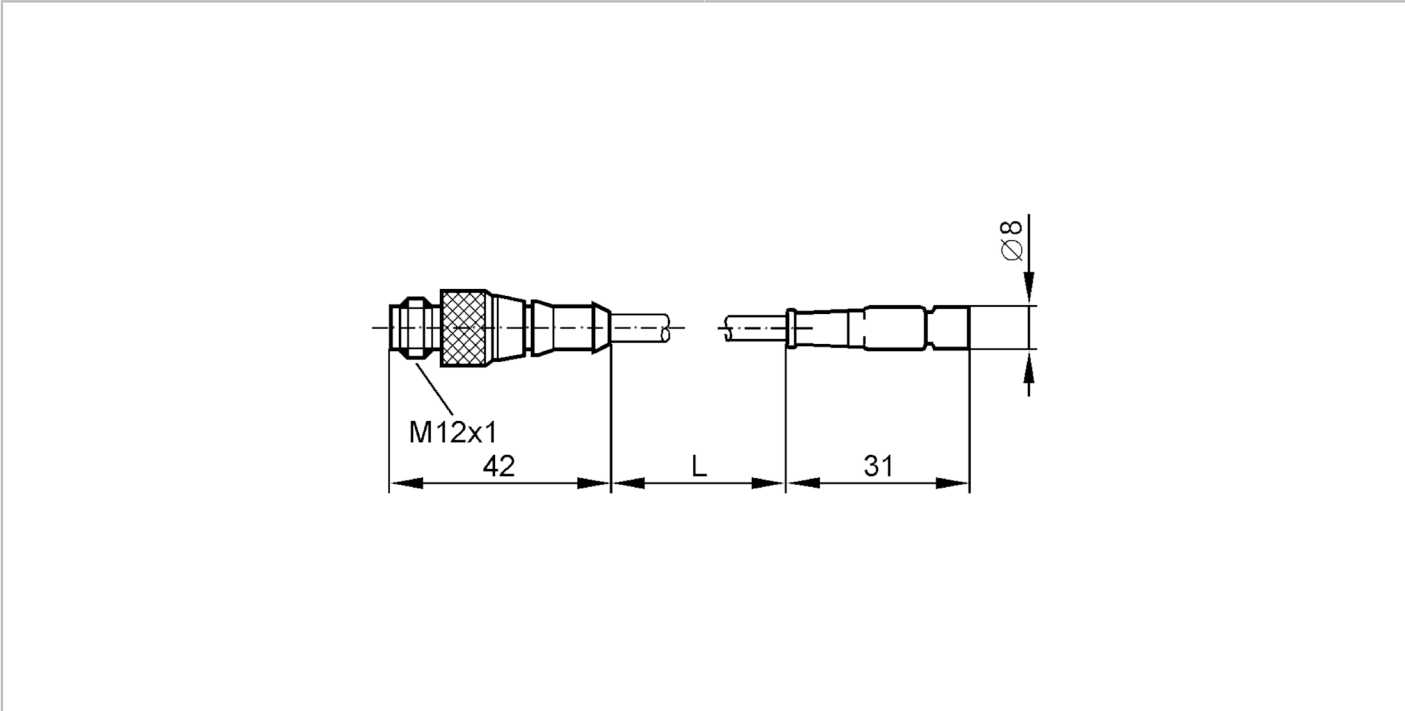

| Electrical data   |     |                   |
|-------------------|-----|-------------------|
| Operating voltage | [V] | < 60 AC / < 75 DC |
| Protection class  |     | III               |

| Operating conditions |      |          |
|----------------------|------|----------|
| Ambient temperature  | [°C] | -25...90 |
| Protection           |      | IP 67    |

| Mechanical data       |  |                      |
|-----------------------|--|----------------------|
| Materials             |  | TPU                  |
| Moulded-body material |  | TPU                  |
| Material nut          |  | brass, nickel-plated |

| Remarks       |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



# E10557




## Connection cable

VDOGG030--S01,5A03STGH030MSS

### Electrical connection

Cable: 1.5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

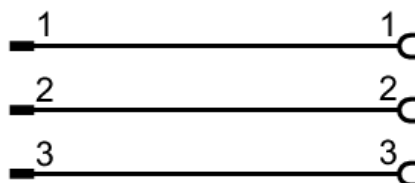

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

