

E10588



Connecting cable with socket

ADOGH050MSS0005A05

Article no longer available - archive entry

Alternative articles: EVC071
When selecting an alternative article and accessories please note that technical data may differ!



Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10588



Connecting cable with socket


ADOGH050MSS0005A05

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5.2 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

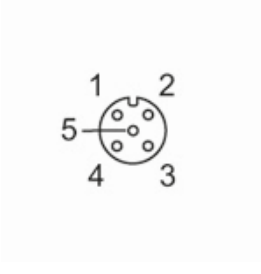

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white