


E10728



Connecting cable with socket

ADOAF032VAS0005A03

Article no longer available - archive entry

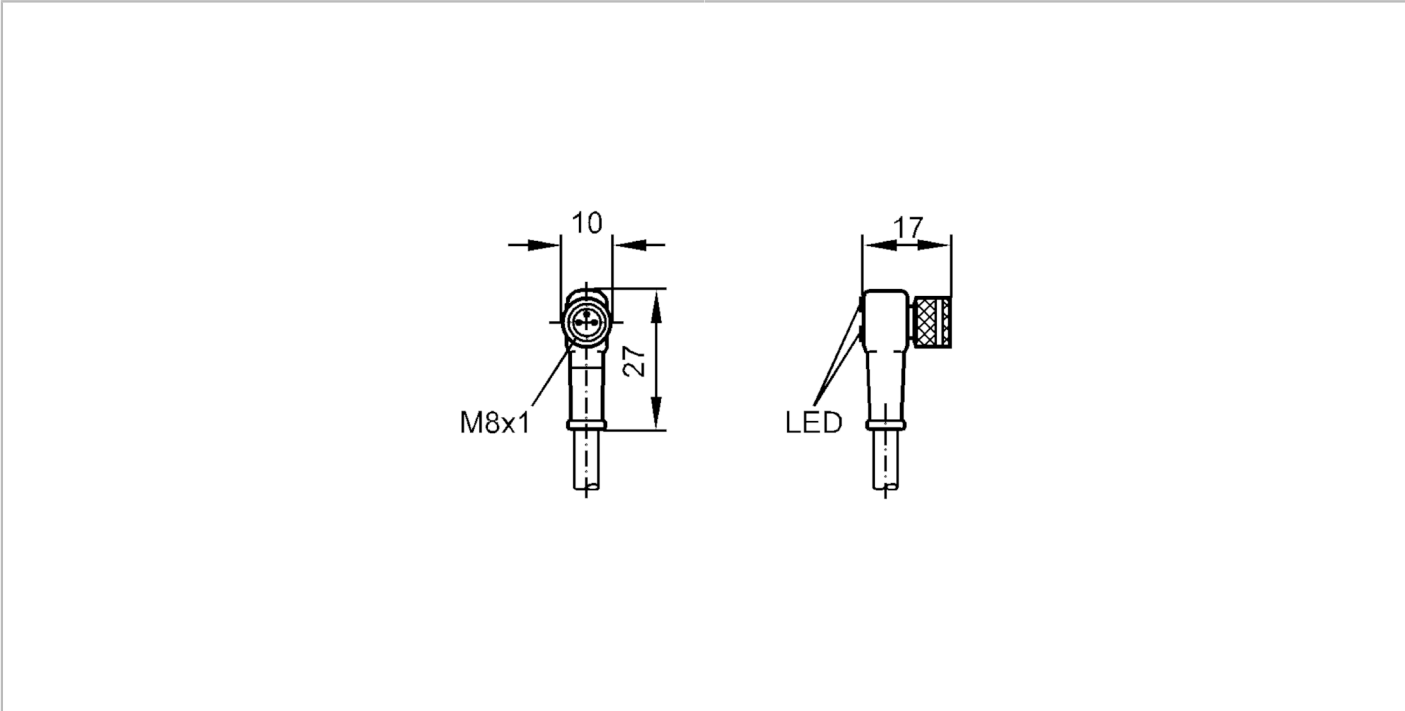

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel (303/1.4305)
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10728



Connecting cable with socket

 
ADOAF032VAS0005A03

Electrical connection


Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: stainless steel (303/1.4305)



Connection

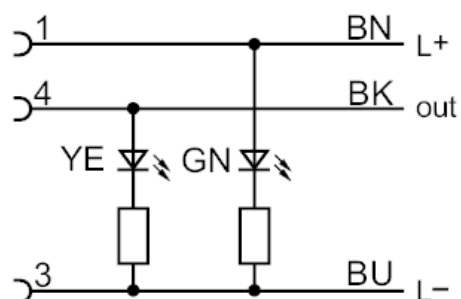

BK =	Core colours :
BN =	black
BU =	brown
	blue