


Connecting cable with socket

ADOAH040MSN0005A04

Article no longer available - archive entry

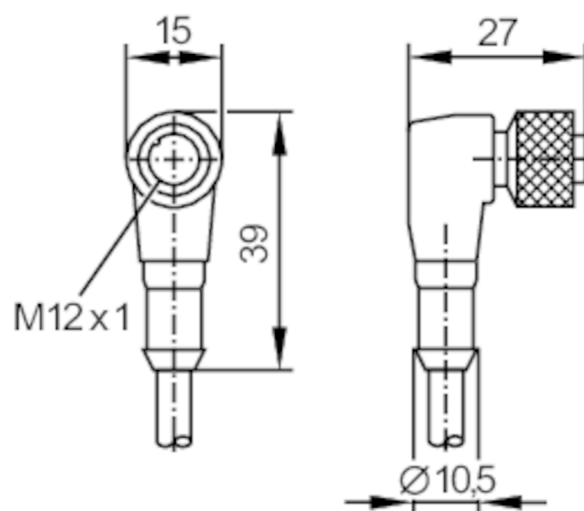

Application

Application

Ex zone 1

Electrical data

Operating voltage

[V]

< 15 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

27 x 15 x 39

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Remarks

When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.

The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity

1 pcs.

E11694



Connecting cable with socket


ADOAH040MSN0005A04

Electrical connection


Cable: 5 m, PUR / PVC, blue, Ø 5 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

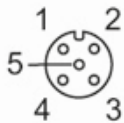

Connection

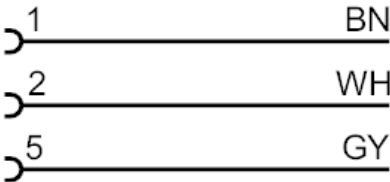

BN = Core colours : brown
GY = grey
WH = white