

E11731




Splitter box

ZDO6H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: EBC007
When selecting an alternative article and accessories please note that technical data may differ!

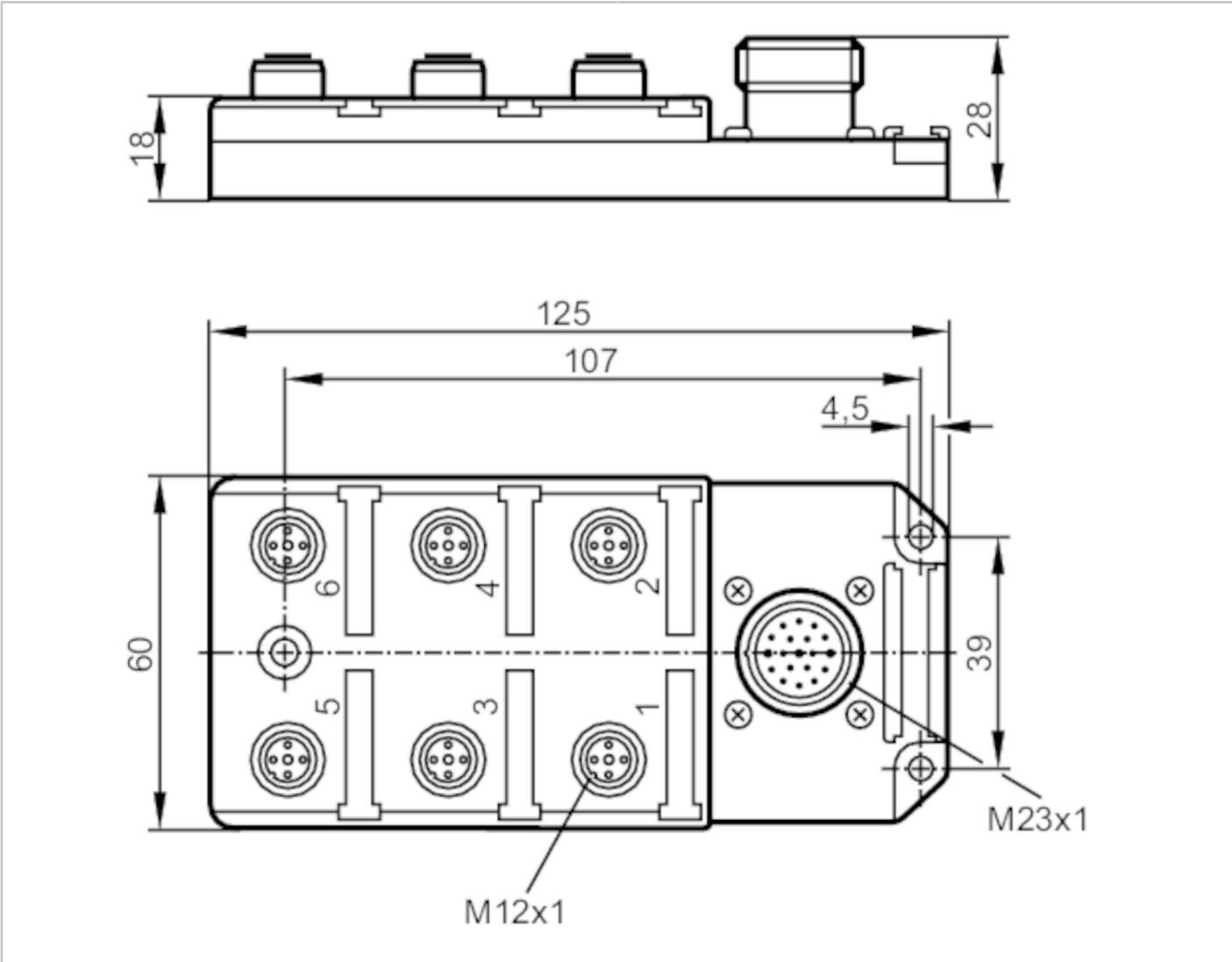

Application

Special feature

Free from silicone; Gold-plated contacts

Free from silicone

yes

Electrical data

Operating voltage

[V]

< 60 AC / < 75 DC

Protection class

II

Max. current load per
module/slot

[A]

4

Max. current load total

[A]

10

Operating conditions

Ambient temperature

[°C]

-15...80

Protection

IP 67

E11731



Splitter box


ZDO6H050MSS0000-00STAK190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 125
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		6
Connector type		M12

Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

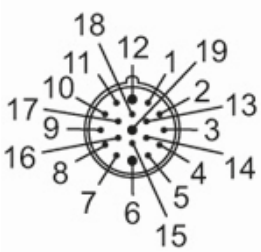

Connection

+	19	1 (1...6)	C
-	6	3 (1...6)	C
⏏	12	5 (1...6)	C
	15	4 (1)	C
	7	2 (1)	C
	5	4 (2)	C
	4	2 (2)	C
	16	4 (3)	C
	8	2 (3)	C
	3	4 (4)	C
	14	2 (4)	C
	17	4 (5)	C
	9	2 (5)	C
	2	4 (6)	C
	13	2 (6)	C

E11731



Splitter box

ZDO6H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

