




Connecting cable with socket

ADOAF030VAS0020E03

Article no longer available - archive entry

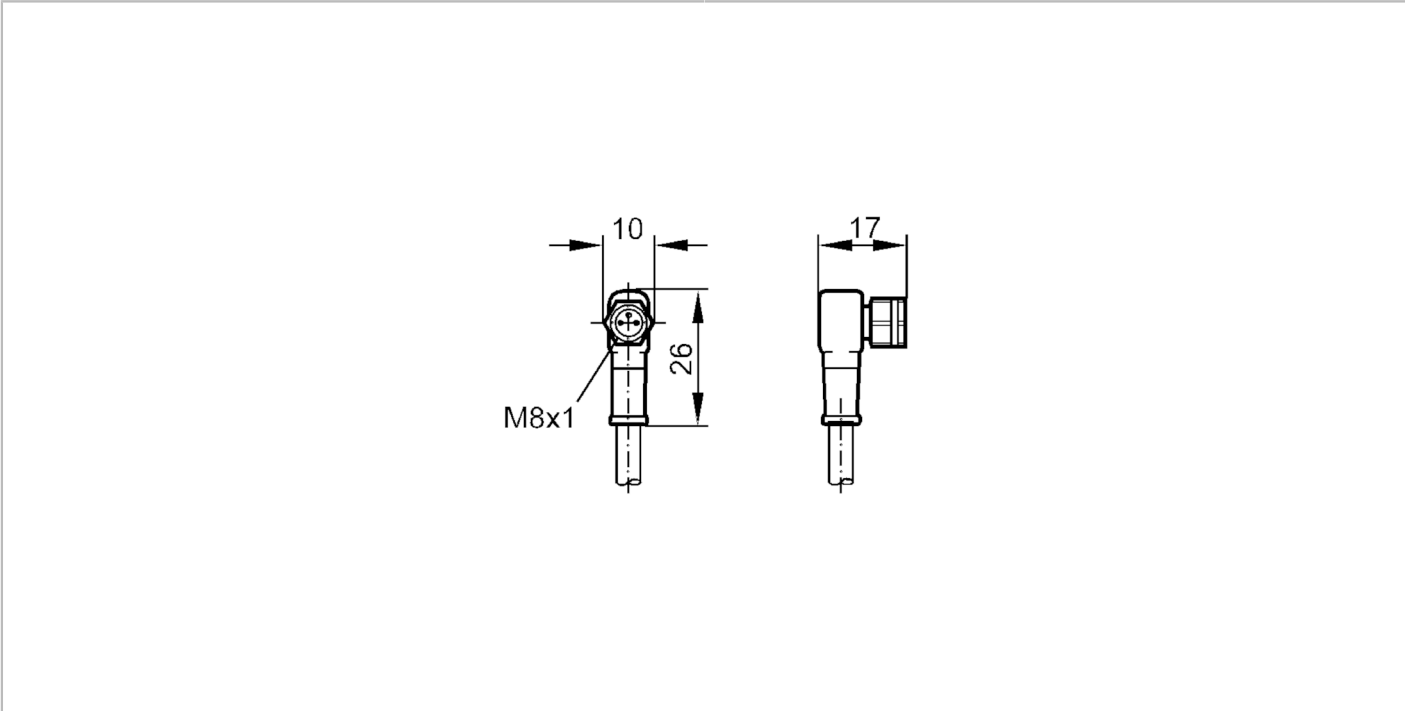

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Dimensions	[mm]	17 x 10 x 26
Materials		TPU
Moulded-body material		TPU
Material nut		stainless steel (303/1.4305)

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 20 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm²		

Electrical connection - socket		
Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: stainless steel (303/1.4305)		

 

E11091



Connecting cable with socket

ADOAF030VAS0020E03

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue