


E11168



Jumper cable with valve plug

VSGH030MSS0001HDOAB031PLS

Article no longer available - archive entry

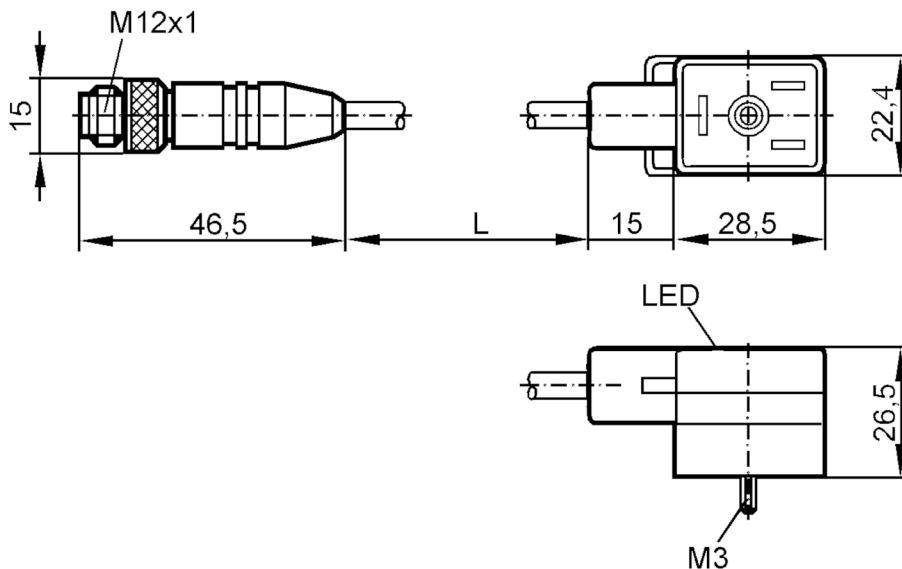

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Overvoltage protection yes; (VDR)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Displays / operating elements

Display switching status 1 x LED, yellow

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.



Jumper cable with valve plug

VSGH030MSS0001HDOAB031PLS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 1 m, PUR, Halogen-free, grey; 3 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU; Locking: brass, nickel-plated

