


## Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

phase-out article

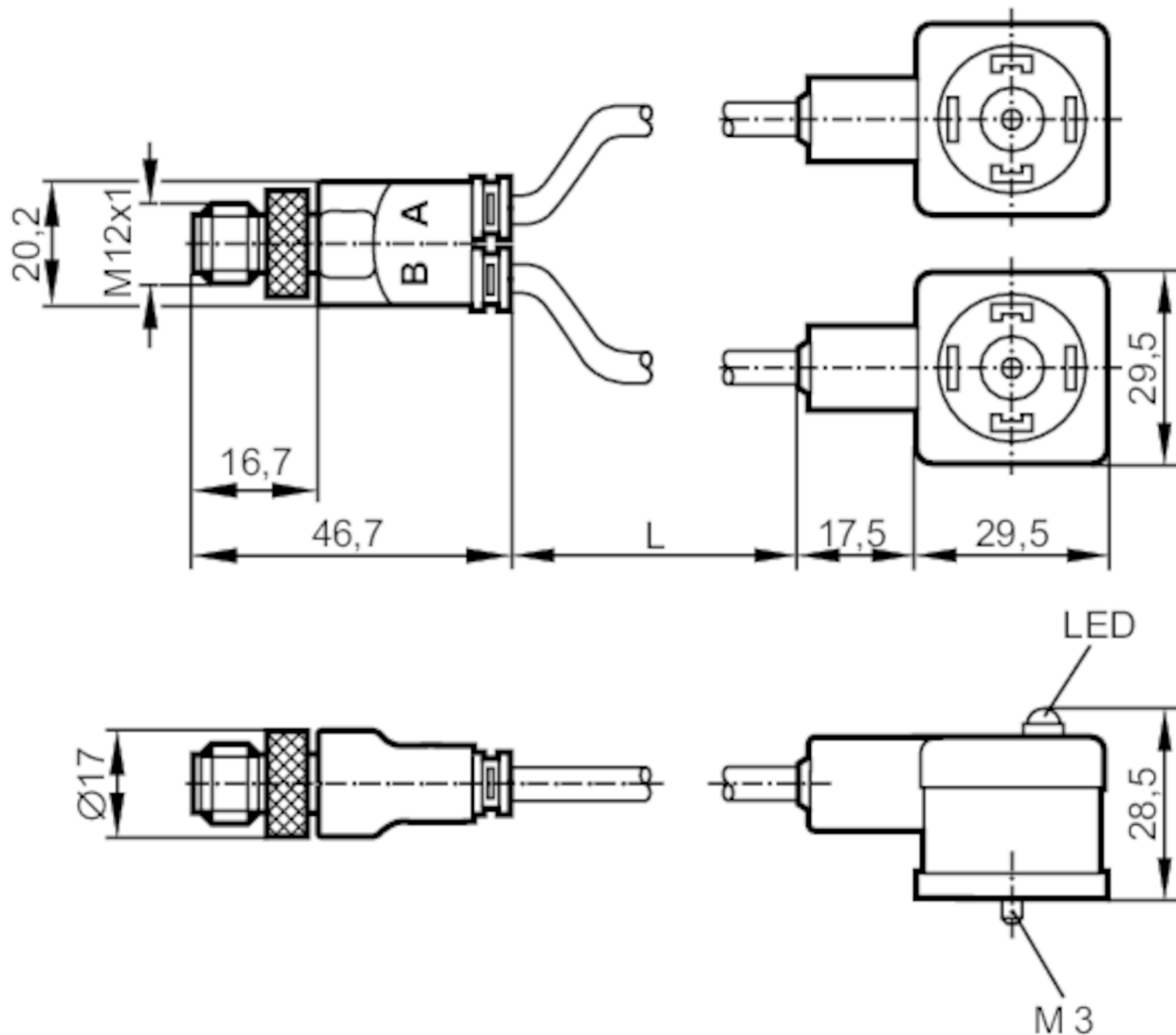

## Application

Special feature

Halogen-free

## Electrical data

Operating voltage [V]

10...30 DC

Overvoltage protection

yes; (VDR)

## Operating conditions

Ambient temperature [°C]

-25...90

Protection

IP 65

## Mechanical data

Weight [g]

350.2

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated


# E12068




## Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

| Displays / operating elements |                     |                 |
|-------------------------------|---------------------|-----------------|
| Display                       | switching status    | 2 x LED, yellow |
| Accessories                   |                     |                 |
| Items supplied                | screw               |                 |
|                               | panel for labelling |                 |
| Remarks                       |                     |                 |
| Pack quantity                 | 1 pcs.              |                 |
| Electrical connection - plug  |                     |                 |
| Connection                    |                     |                 |

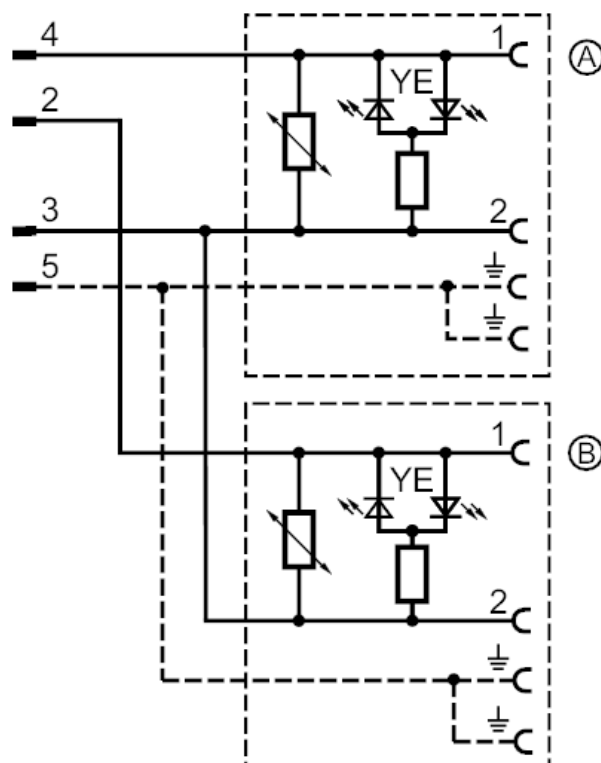

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

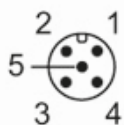

# E12068



## Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

### Electrical connection

Cable: 3 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm<sup>2</sup> (16 x Ø 0.2 mm )

### Electrical connection - socket

Connector: 2 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

