


E12366



Adapter socket

EDOGF040MSS00,5E04 (M8)

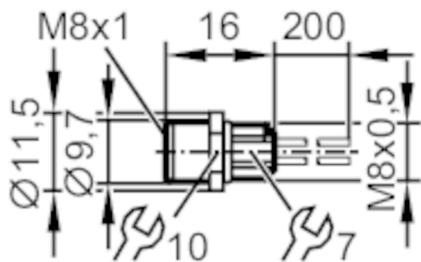

1 O-ring



Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	12.5
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E12366



Adapter socket

EDOGF040MSS00,5E04 (M8)

Electrical connection


Cable: 0.5 m, PVC; 4 x 0.25 mm²

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: brass, nickel-plated



Connection

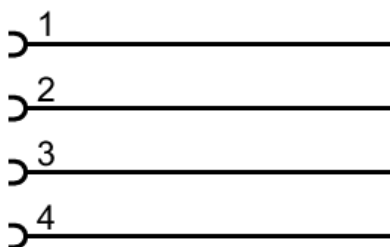

BK =	Core colours :	black
BN =		brown
BU =		blue
WH =		white