


Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,35M

Article no longer available - archive entry

Alternative articles: E20080

When selecting an alternative article and accessories please note that technical data may differ!

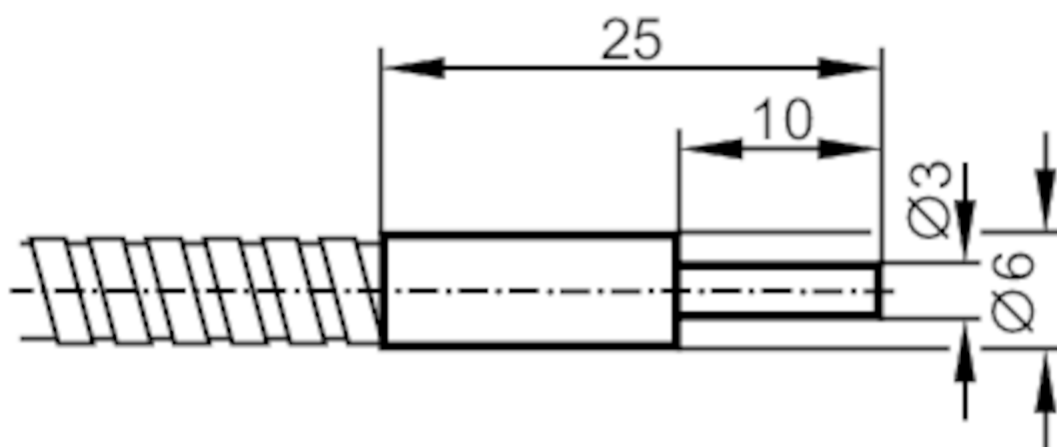

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

350

E20442



Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,35M

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Accessories		
Items supplied		E20102
Remarks		
Pack quantity		1 pcs.