




Fibre optic through-beam sensor

FE-00-M-V-R3/5M

Article no longer available - archive entry

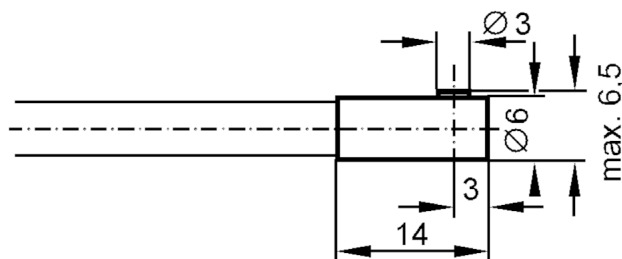

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

50

OUF

Range of fibre optics

[mm]

50

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

0.001

Total length

[mm]

5000

Min. bending radius

[mm]

20

Fibre arrangement



Fibre head material

stainless steel (1.4305 / 303)

Fibre sheath material

metal silicone

Accessories

Items supplied

E20103