


## Fibre optic through-beam sensor

FE-00-A-A-E3/0.8M

Article no longer available - archive entry

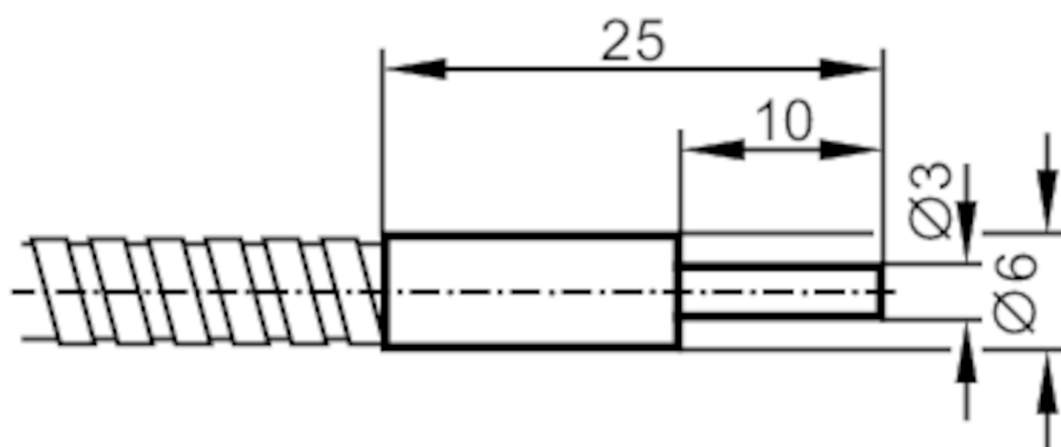

## Application

Function principle

Through-beam sensor

## Detection zone

Range with fibre-optic  
amplifier type

OIF

## OIF

Range of fibre optics

[mm]

100

## Operating conditions

Ambient temperature

[°C]

-40...290

## Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Total length

[mm]

800

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

aluminium

E20399



Fibre optic through-beam sensor

FE-00-A-A-E3/0.8M

| Remarks       |        |
|---------------|--------|
| Pack quantity | 1 pcs. |