


# E2M205



## Adapter cables for cameras with video output

CONNECTION CABLE M16 16M

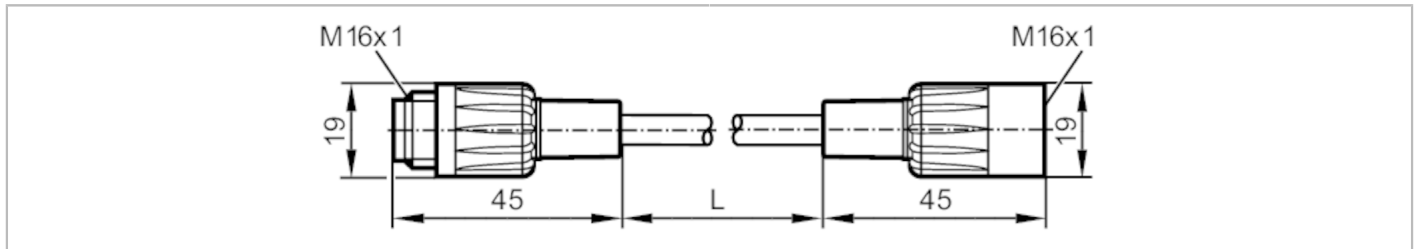

### Application

Special feature	Free from silicone; Gold-plated contacts
Design	camera with video output O2M20x
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 60 DC
Protection class		II
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-45...85
Protection		IP 67

### Mechanical data

Weight	[g]	858.5
Materials		housing: PVC; Sealing: EPDM
Material nut		PVC

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection

Cable: 16 m, PVC, black, Ø 6 mm; 3 x 0.34 mm<sup>2</sup> / AWG 22 + 1 x 0.11 mm<sup>2</sup> / AWG 26

### Electrical connection - plug

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm



# E2M205




## Adapter cables for cameras with video output

CONNECTION CABLE M16 16M

### Electrical connection

#### Connection

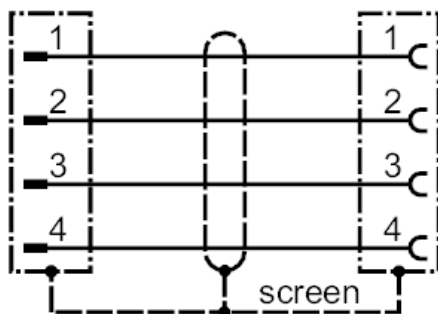

### Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

