




T-piece

T-ADAPT G1 DN25

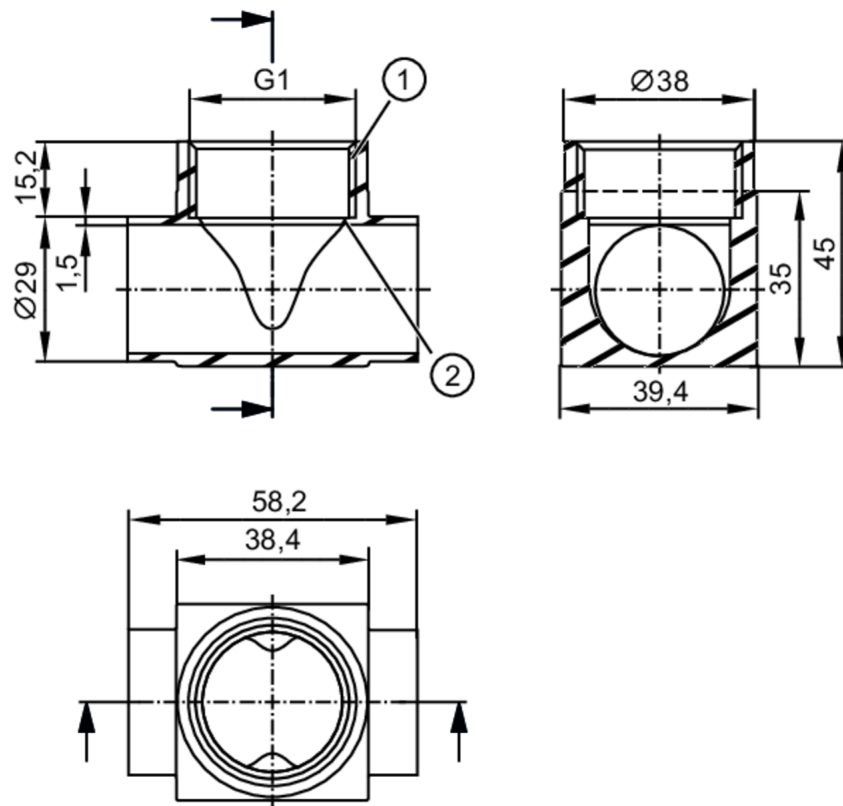

- 1 Aseptoflex Vario
2 sealing area

EC 1935/2004 

Application

Pressure rating [bar]

25

Note on pressure rating

for the connection sensor - adapter

Tests / approvals

Pressure Equipment Directive

A possible classification to PED depends on the application and has to be carried out by the user / operator.

Safety instructions

The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]

305.5

Materials (wetted parts)

stainless steel (316L/1.4404) ; surface characteristics : Ra<0,8 / Rz 4

Sensor connection

G 1 Aseptoflex Vario

Process connection

welding adapter Ø 29 mm

Sealing

Gasket

Accessories

Items supplied

O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054

Accessories (optional)

O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123

Remarks

Pack quantity

1 pcs.