


E60215



Bellows coupling

COUPLING V4A

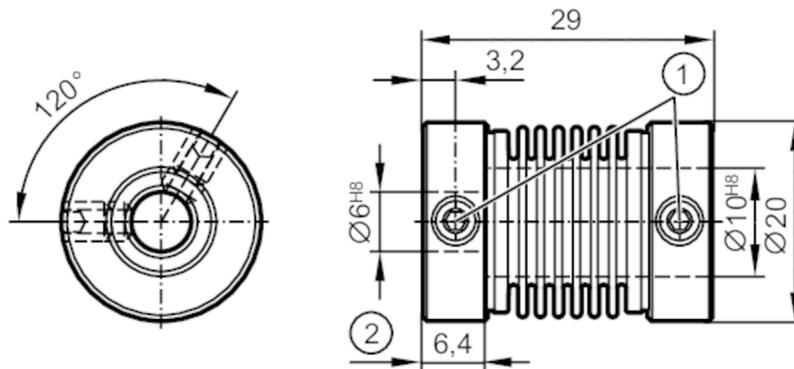

- 1 M4 x 4 - ISO 4029 (4x)
- 2 Depth der Klemmnabe

Mechanical data

Weight	[g]	36.5
Dimensions	[mm]	Ø 20 / L = 29
Materials		flange: 1.4404 (V4A/316L); Bellow: 1.4571 (V4A/316Ti)
Tightening torque	[Nm]	tightening torque screws: 150 Ncm
External diameter D	[mm]	20
Inside diameter 1	[mm]	6
Inside diameter 2	[mm]	10
Depth of the clamping hub	[mm]	6.4
Clamping screw	[mm]	M4 x 4 - ISO 4029 (4x)
Length	[mm]	29
Max. revolution, mechanical	[U/min]	10000
Max. axial shaft misalignment	[mm]	± 0,4
Max. radial shaft misalignment	[mm]	± 0,25
Max. angular displacement	[°]	± 4,0

Remarks

Remarks	The data indicated apply to couplings with the above hub borings at an ambient temperature of 23 °C. The values of radial, angular and axial displacement are maximum values which must not reach their maximum simultaneously while in operation.
Pack quantity	1 pcs.