


# EVC814

## Wirable socket

SDOGH050MSSFKPG

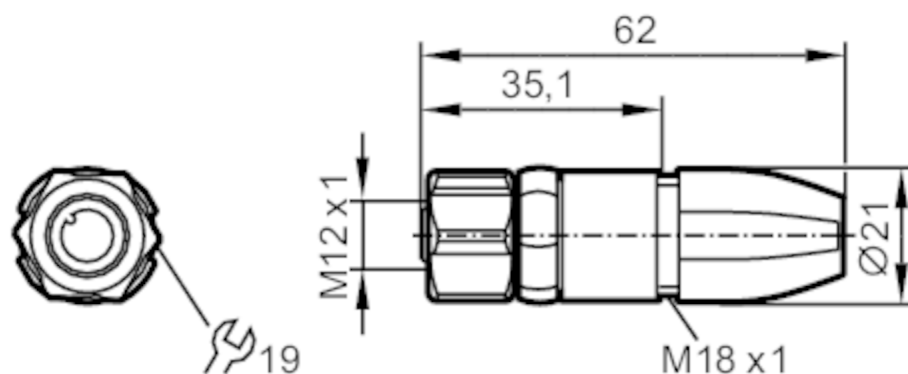

### Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 60 AC/DC
Protection class		II
Max. current load total	[A]	4; (...40 °C)

### Operating conditions

Ambient temperature	[°C]	-25...90
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K

### Mechanical data

Weight	[g]	42.6
Moulded-body material		PA 6.6
Material nut		brass, nickel-plated
Sealing material		FKM

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

# EVC814



## Wirable socket


SDOGH050MSSFKPG

### Electrical connection


screw terminals: 0.25...1 mm<sup>2</sup>; Cable sheath: Ø 3.5...6 mm; AWG 23...17

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6, orange; Locking: brass, nickel-plated; Sealing: FKM; Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm; Take into account the maximum value of the counterpart!

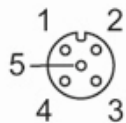

### Connection

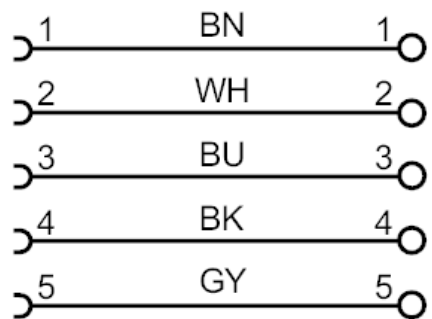

	Core colours
BN =	brown
WH =	white
BU =	blue
BK =	black
GY =	grey
	colours to DIN EN 60947-5-2