

IM504A




Inductive sensor

IMC4020BCPKG/US-100-DPA/3D

Article no longer available - archive entry

Alternative articles: IM512A

When selecting an alternative article and accessories please note that technical data may differ!

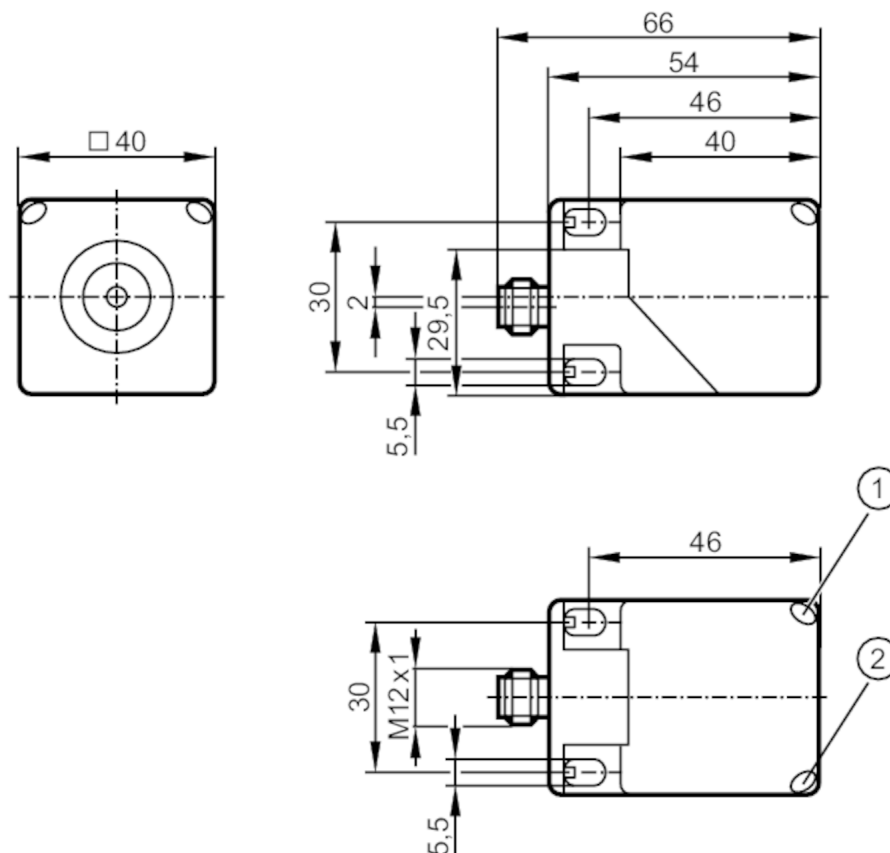

- 1 LED yellow
- 2 LED green



Product characteristics

Electrical design	PNP
Output function	complementary
Sensing range [mm]	20
Housing	rectangular
Dimensions [mm]	40 x 40 x 54

Electrical data

Operating voltage [V]	10...30 DC; (when used outside the hazardous area: 10...36)
Current consumption [mA]	< 20
Protection class	II
Reverse polarity protection	yes

Outputs

Electrical design	PNP
Output function	complementary

IM504A



Inductive sensor

IMC4020BCPKG/US-100-DPA/3D

Max. voltage drop switching output DC	[V]	2.5
Max. leakage current	[mA]	0.1; (only in 2-wire operation)
Permanent current rating of switching output DC	[mA]	200
Switching frequency DC	[Hz]	100
Short-circuit protection		yes
Type of short-circuit protection		pulsed
Overload protection		yes

Detection zone		
Sensing range	[mm]	20
Operating distance	[mm]	0...16.2

Accuracy / deviations		
Correction factor		steel: 1 / stainless steel: 0.7 / brass: 0.4 / aluminium: 0.4 / copper: 0.3
Hysteresis	[% of Sr]	1...20

Operating conditions		
Ambient temperature	[°C]	-20...50
Note on ambient temperature		when used outside the hazardous area: -25...70 °C
Protection		IP 5x; (when used outside the hazardous area: IP 67)

Tests / approvals		
ATEX marking		II 3D Ex tD A22 IP67 T80°C X
		II 3G Ex nA II T6 X
EMC	EN 61000-4-2 ESD	8 kV CD / 6 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-5 Surge	0,5 kV line to line, Ri: 2 Ohm
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B

Mechanical data		
Weight	[g]	0.163
Housing		rectangular
Mounting		flush mountable
Dimensions	[mm]	40 x 40 x 54
Materials		housing: PA; sensing face: PA black; end cap: PA; clamp: orange; screw: stainless steel (304CU/1.4567)

Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks		
Pack quantity		1 pcs.

IM504A



Inductive sensor

IMC4020BCPKG/US-100-DPA/3D

Electrical connection - plug

Connector: 1 x M12; coding: A; Locking: locking, rotatable, stainless steel (316L/1.4404)



Connection

