


E3R100



Connection cable

HFM Y CABLE 2 X S/S/M S/D/M A 2,0M

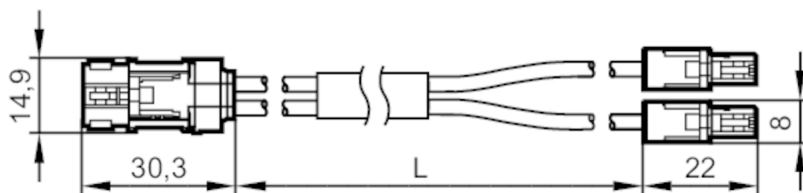

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Damping	[dB/m]	1.6
Internal resistance (Ri)	[Ω]	50; (± 3 %)

Operating conditions

Ambient temperature	[°C]	-10...60
Ambient temperature (moving)	[°C]	-10...60
Protection		IP 54

Mechanical data

Weight	[g]	91.62
Min. bending radius	[mm]	16.5; (single; 15 x 3,3 mm min. 10 x cable diameter)
Materials		housing: : PBT-GF20

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - 2D/3D camera

Connector: 1 x HFM-Dual, straight

Electrical connection

Cable: 2 m, black, Ø 3.3 mm

Electrical connection - Video Processing Unit

Connector: 2 x HFM-Single, straight