


E10564



Connecting cable with socket

ADOAH042MSS0002B03

Article no longer available - archive entry

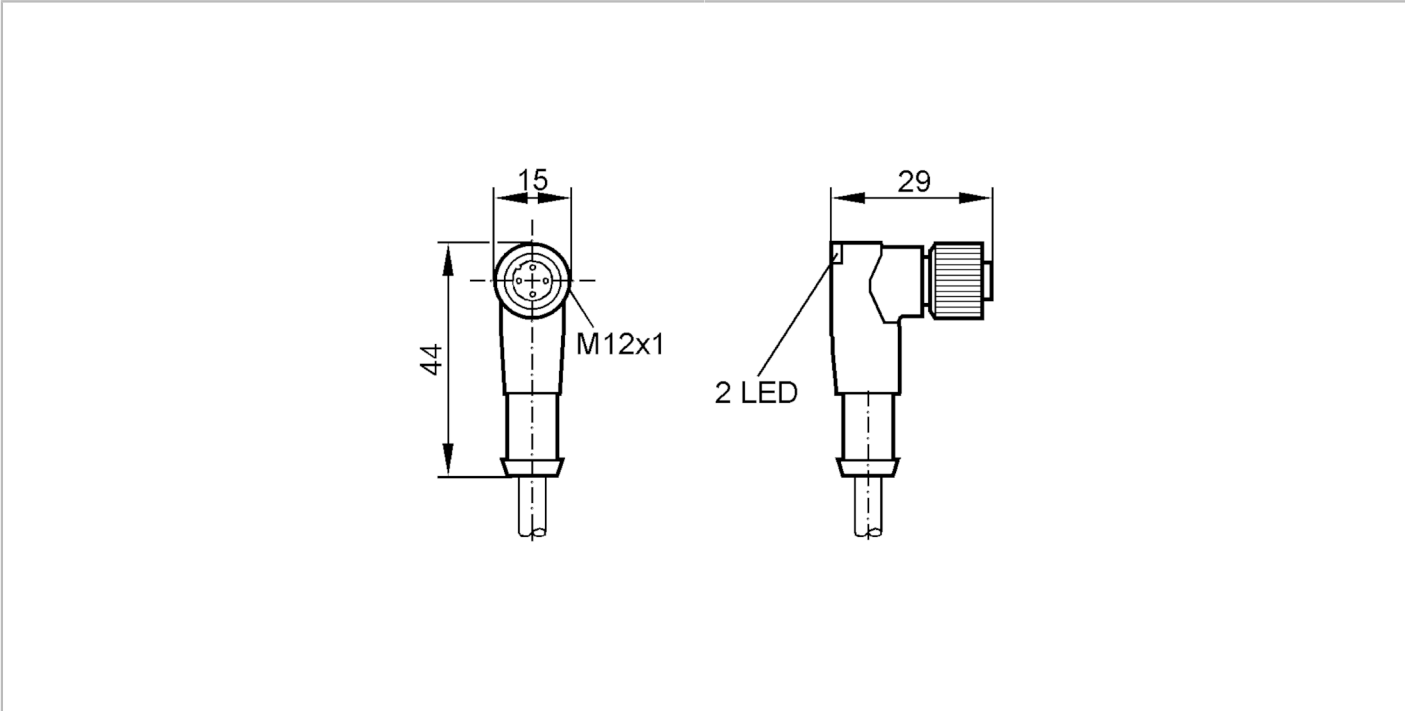

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-20...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	29 x 15 x 44
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		aluminium
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10564



Connecting cable with socket

ADOAH042MSS0002B03

Electrical connection


Cable: 2 m, PUR, orange, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminium



Connection

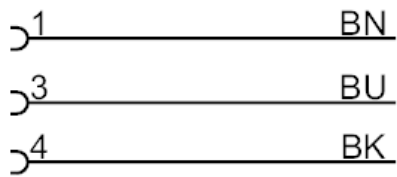

BN = Core colours :
BK = brown
BU = black
 blue