

E10686




Connecting cable with socket

ADOGH040MSS0005B04

Article no longer available - archive entry

Alternative articles: EVC002
When selecting an alternative article and accessories please note that technical data may differ!

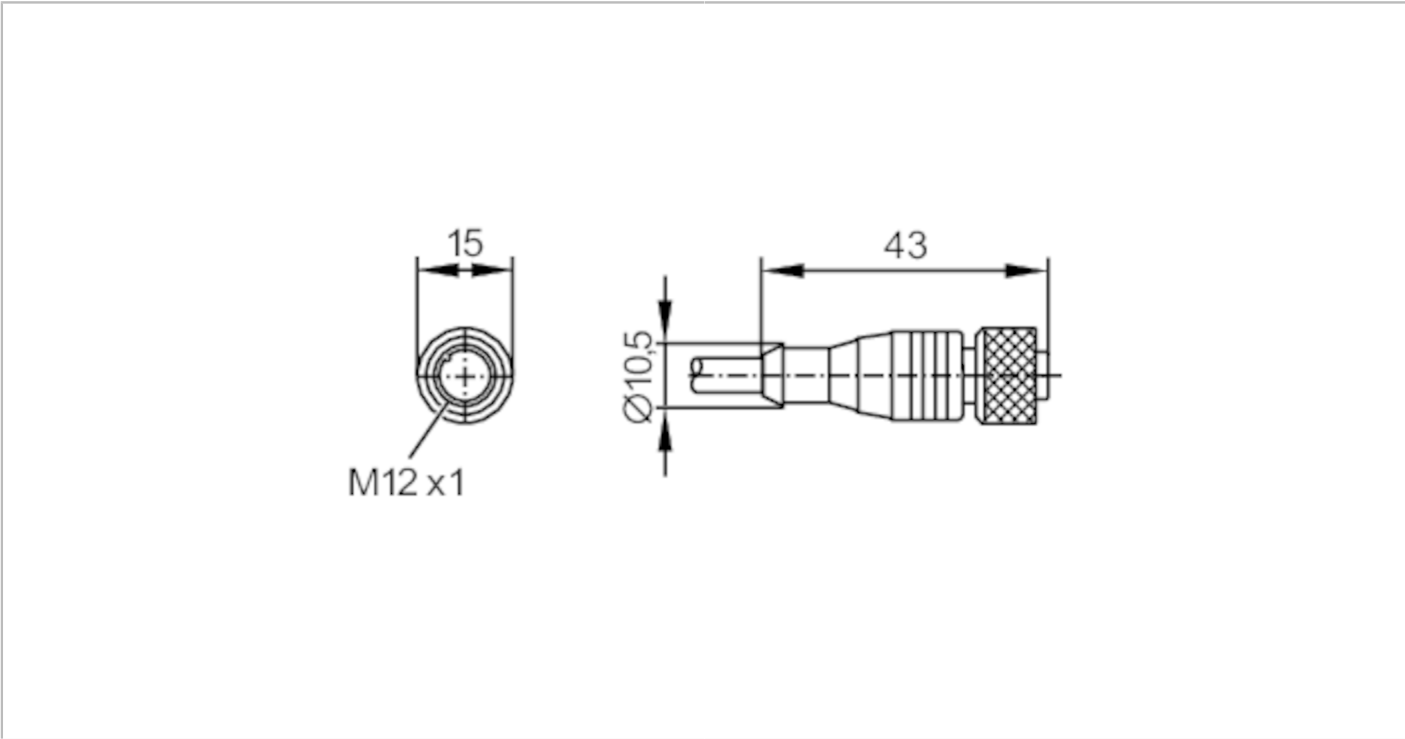

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10686



Connecting cable with socket

ADOGH040MSS0005B04

Electrical connection


Cable: 5 m, PUR, orange; 4 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

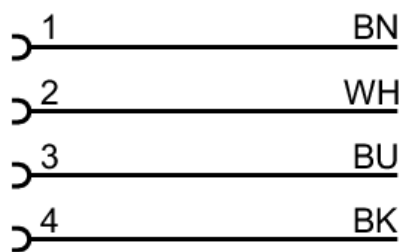

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white