

Connecting cable with socket

ADOAH043MSS0005H04

Article no longer available - archive entry



Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Outputs

Electrical design

PNP

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

27 x 15 x 39

Materials

TPU transparent

Moulded-body material

TPU, transparent

Material nut

brass, nickel-plated

Displays / operating elements

Display

switching status

2 x LED, yellow

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.

E10855



Connecting cable with socket

ADOAH043MSS0005H04

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; 4 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated



Connection

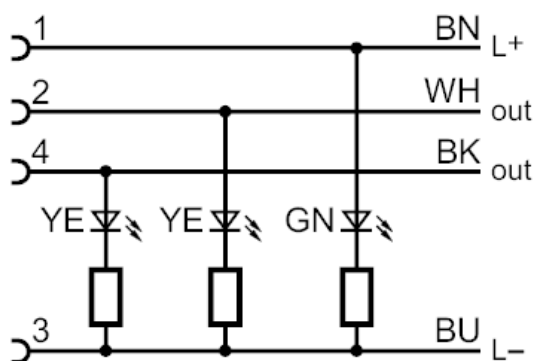

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white