

E10910




Connecting cable with socket

ADOAH040SCS0005I04

Article no longer available - archive entry

Alternative articles: EVW005

When selecting an alternative article and accessories please note that technical data may differ!

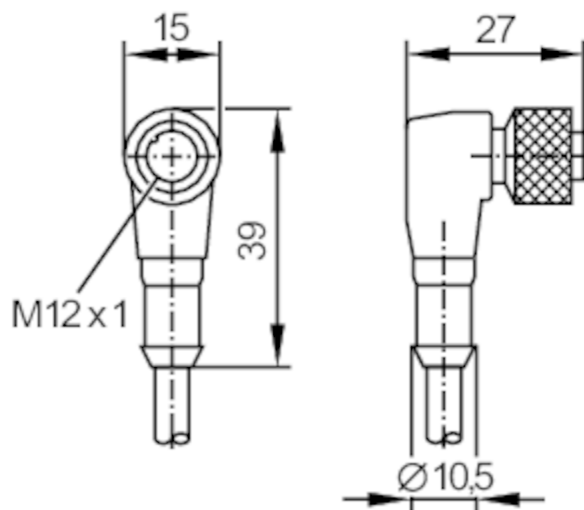

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter

Remarks

Pack quantity	1 pcs.
---------------	--------

E10910



Connecting cable with socket

 
ADOAH040SCS0005I04

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

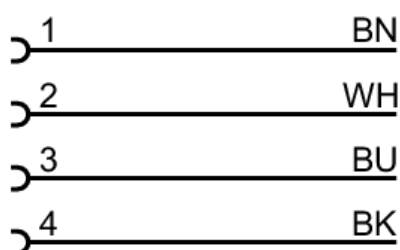

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white