


Splitter box

ZDO6H059MSS0000-00STAM190MSS

Article no longer available - archive entry

Alternative articles: EBC008

When selecting an alternative article and accessories please note that technical data may differ!

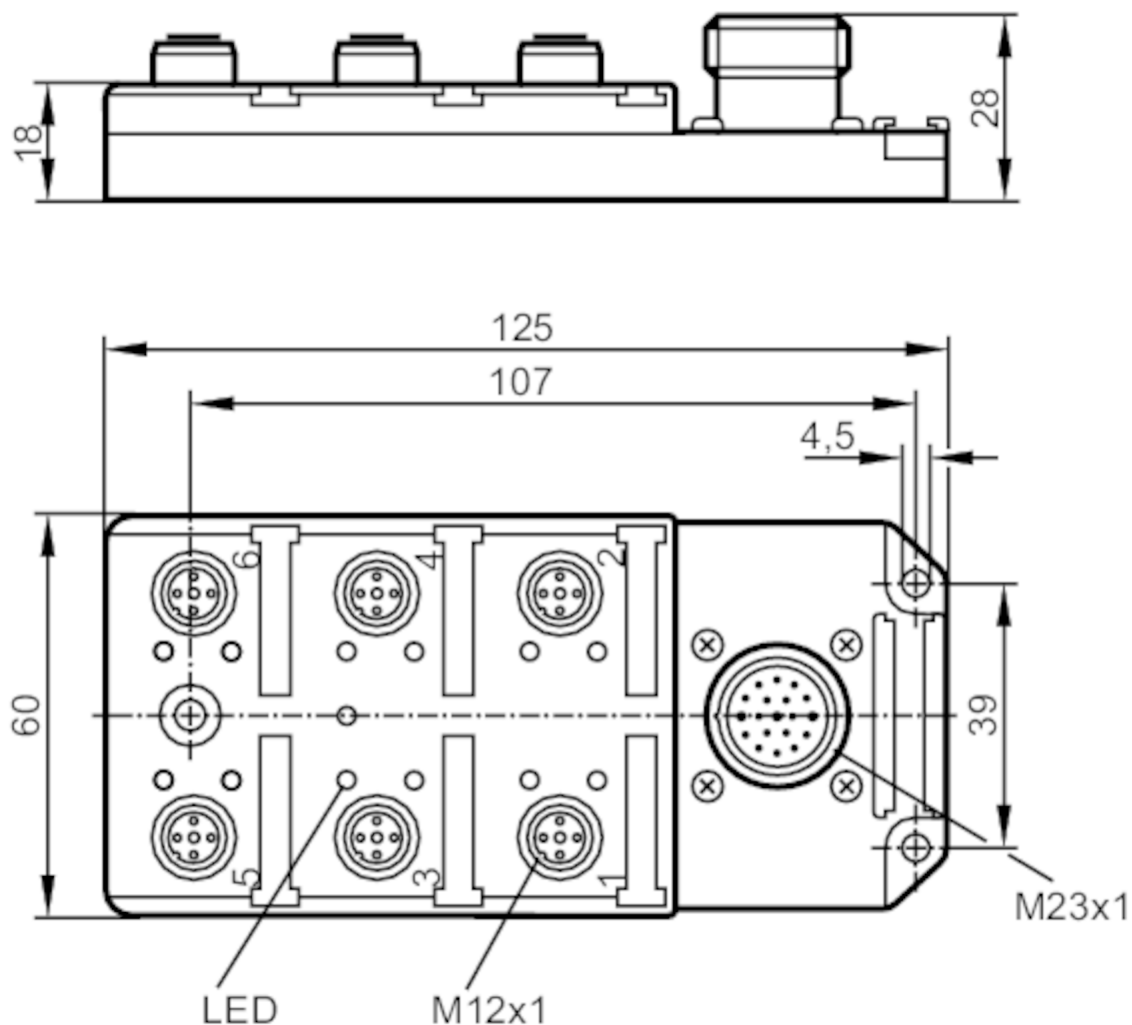

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

E10946



Splitter box

ZDO6H059MSS0000-00STAM190MSS


Mechanical data		
Dimensions	[mm]	28 x 60 x 125
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		6
Connector type		M12

Displays / operating elements		
Display	switching status	12 x LED, yellow
	operation	1 x LED, green

Remarks		
Pack quantity		1 pcs.

Electrical connection - Connection


Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

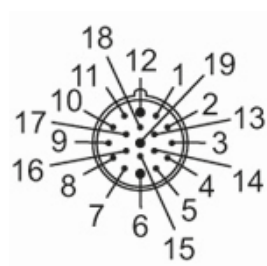

Splitter box

ZDO6H059MSS0000-00STAM190MSS

Connection

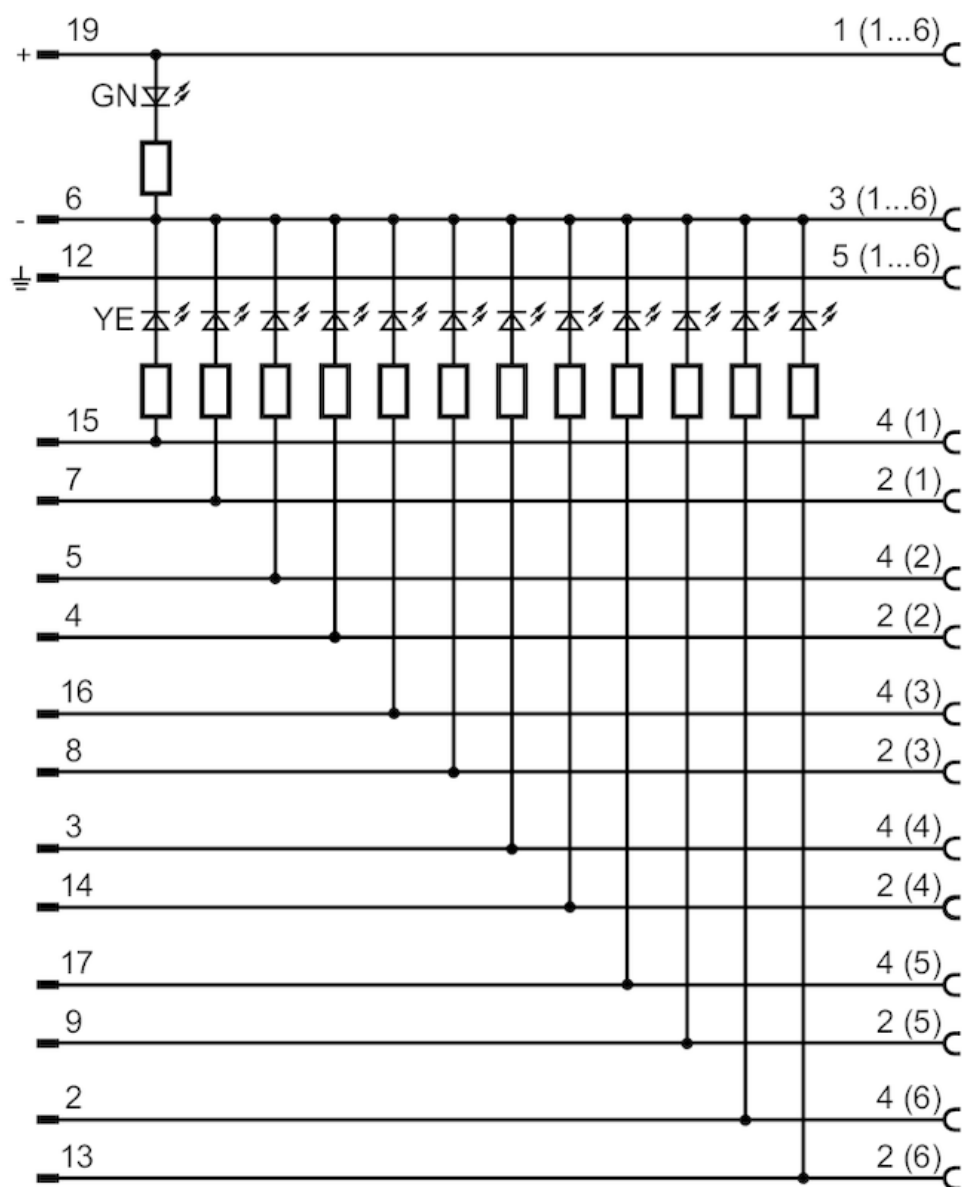

E10946



Splitter box

ZDO6H059MSS0000-00STAM190MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

