


Wirable socket

SDOAH041PLSFKPG

Article no longer available - archive entry

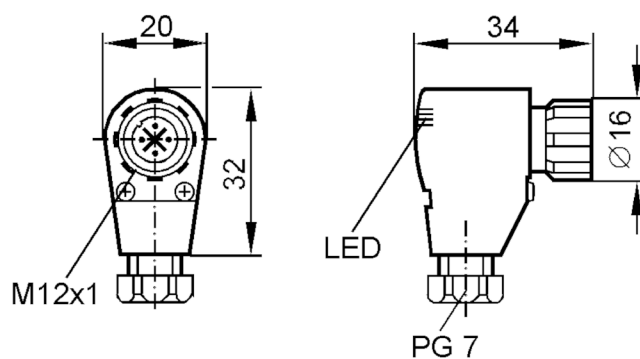

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	NPN
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-30...80
---------------------	------	----------

Protection	IP 65
------------	-------

Mechanical data

Dimensions	[mm]	20 x 34 x 32
------------	------	--------------

Materials	PA
-----------	----

Moulded-body material	PA
-----------------------	----

Material nut	PA
--------------	----

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Remarks

Pack quantity	1 pcs.
---------------	--------

E10099



Wirable socket

 
SDOAH041PLSFKPG

Electrical connection

terminals: ...0.5 mm²; Cable gland: PG 7

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: PA



Connection

