


Connecting cable with socket

ADOAH040PLS0005E03

Article no longer available - archive entry

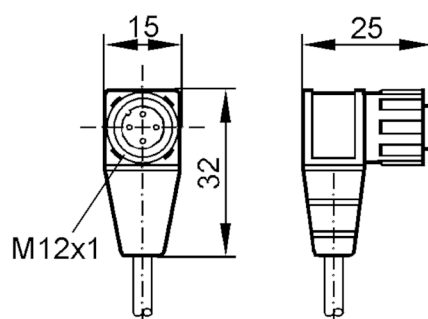

Electrical data

Operating voltage	[V]	10...55 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	25 x 15 x 32
Materials		PUR
Moulded-body material		PUR
Material nut		PUR

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC; 3 x 0.34 mm² (7 x Ø 0.25 mm)

Electrical connection - socket

 Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: PUR



E10128



Connecting cable with socket

ADOAH040PLS0005E03

Connection

