

E10302




Connecting cable with socket

ADOGH040MSS0002A04

Article no longer available - archive entry

Alternative articles: EVC001
When selecting an alternative article and accessories please note that technical data may differ!

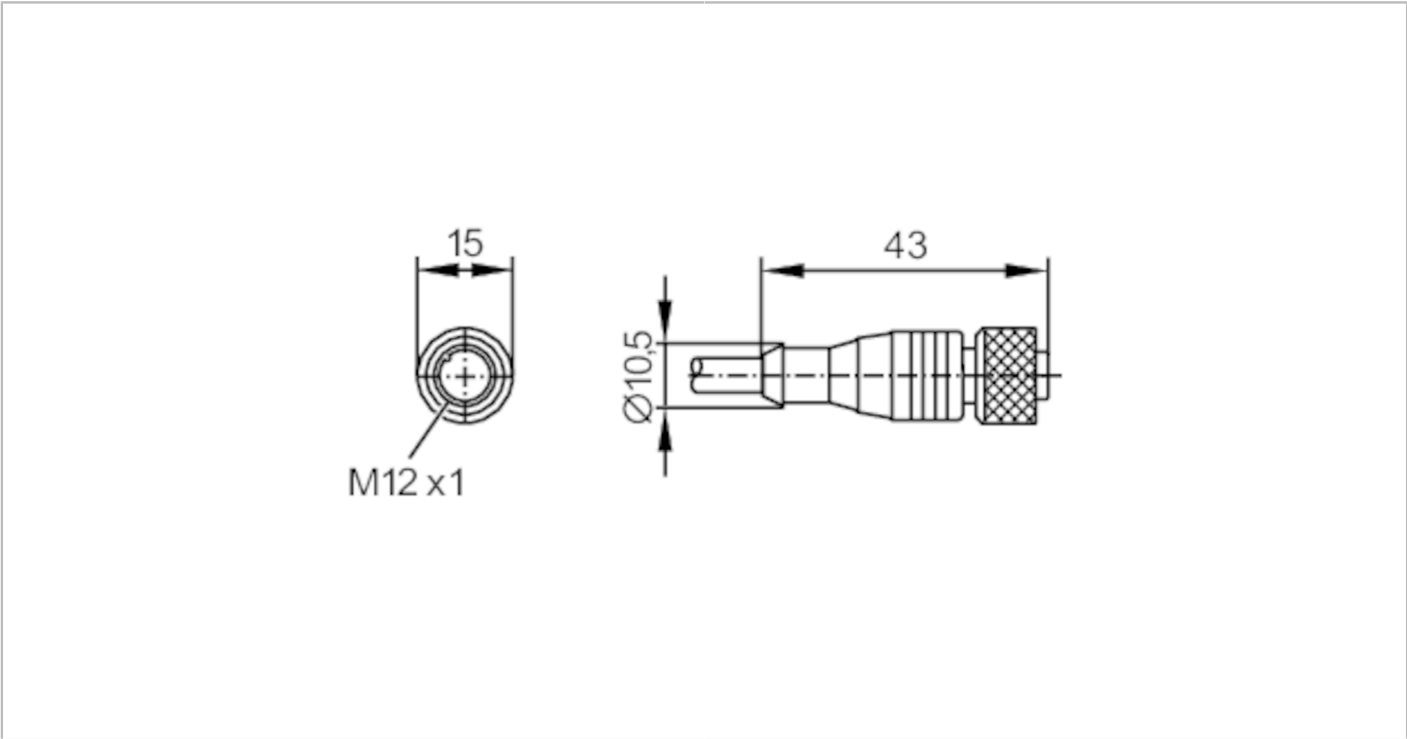

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10302



Connecting cable with socket

ADOGH040MSS0002A04

Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

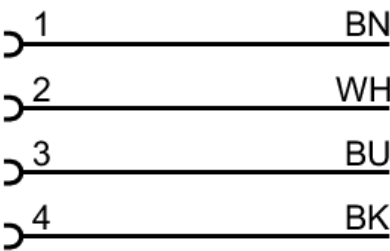

BN =	Core colours :
BK =	brown
BU =	black
WH =	blue
	white