


Splitter box

ZDO4H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: EBC003

When selecting an alternative article and accessories please note that technical data may differ!

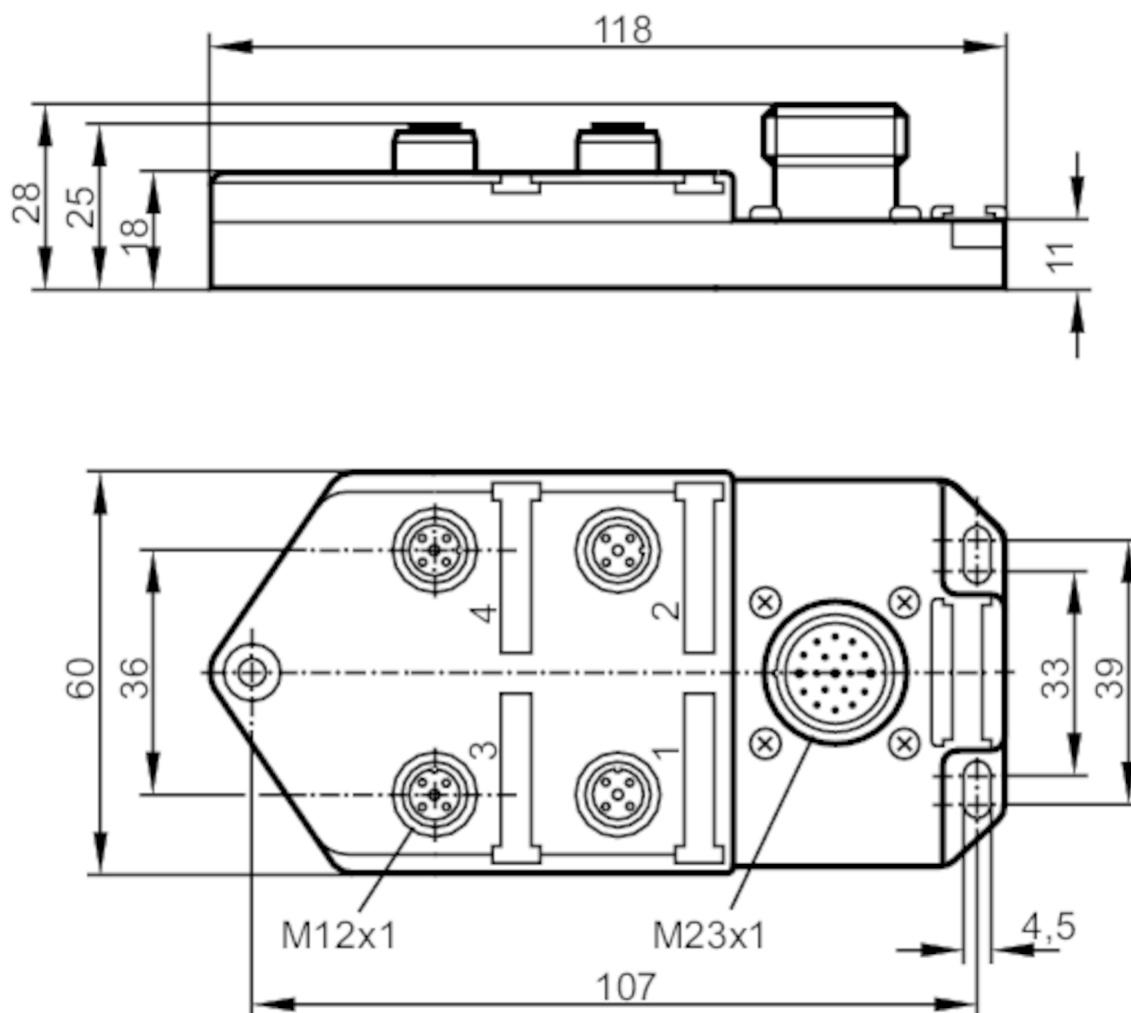

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

E11728



Splitter box


ZDO4H050MSS0000-00STAK190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 118
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		4
Connector type		M12


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

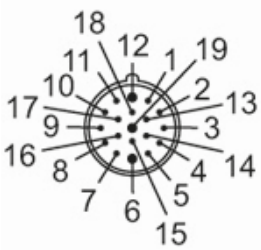

Connection

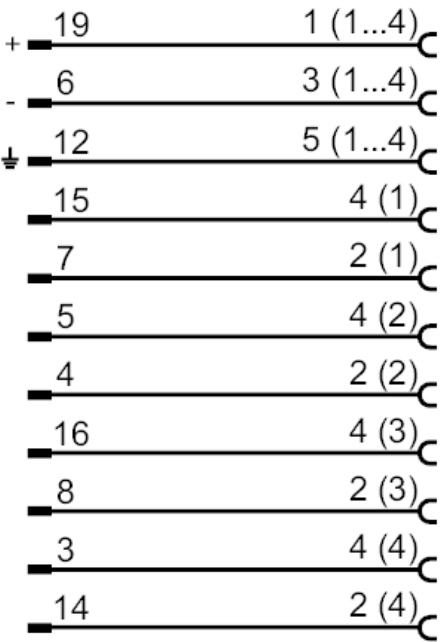

E11728



Splitter box

ZDO4H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

