


E11840



Wirable plug

SSTGH040MSSFKSK

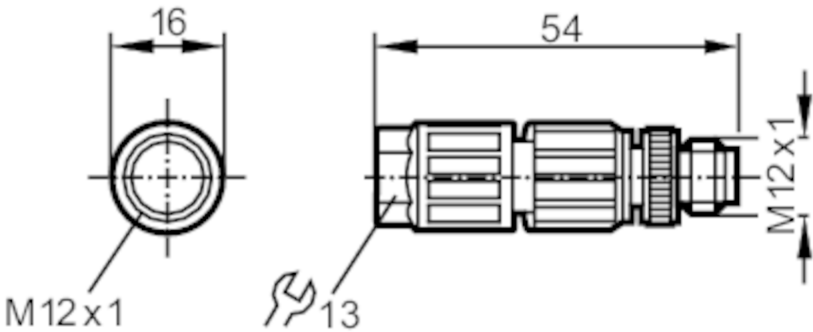

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...60
Protection		IP 67
Mechanical data		
Weight	[g]	11.8
Dimensions	[mm]	16 x 16 x 54
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		PA 6.6
Remarks		
Pack quantity		1 pcs.

Electrical connection	
insulation displacement technology: 0.14...0.34 mm²; Cable sheath: Ø 3.5...6 mm	
Electrical connection - plug	

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: PA 6.6



E11840

Wirable plug

SSTGH040MSSFKSK



Connection

