

E11021




Splitter box

ZDO8H05HMSS0005H19

Article no longer available - archive entry

Alternative articles: EBC024

When selecting an alternative article and accessories please note that technical data may differ!

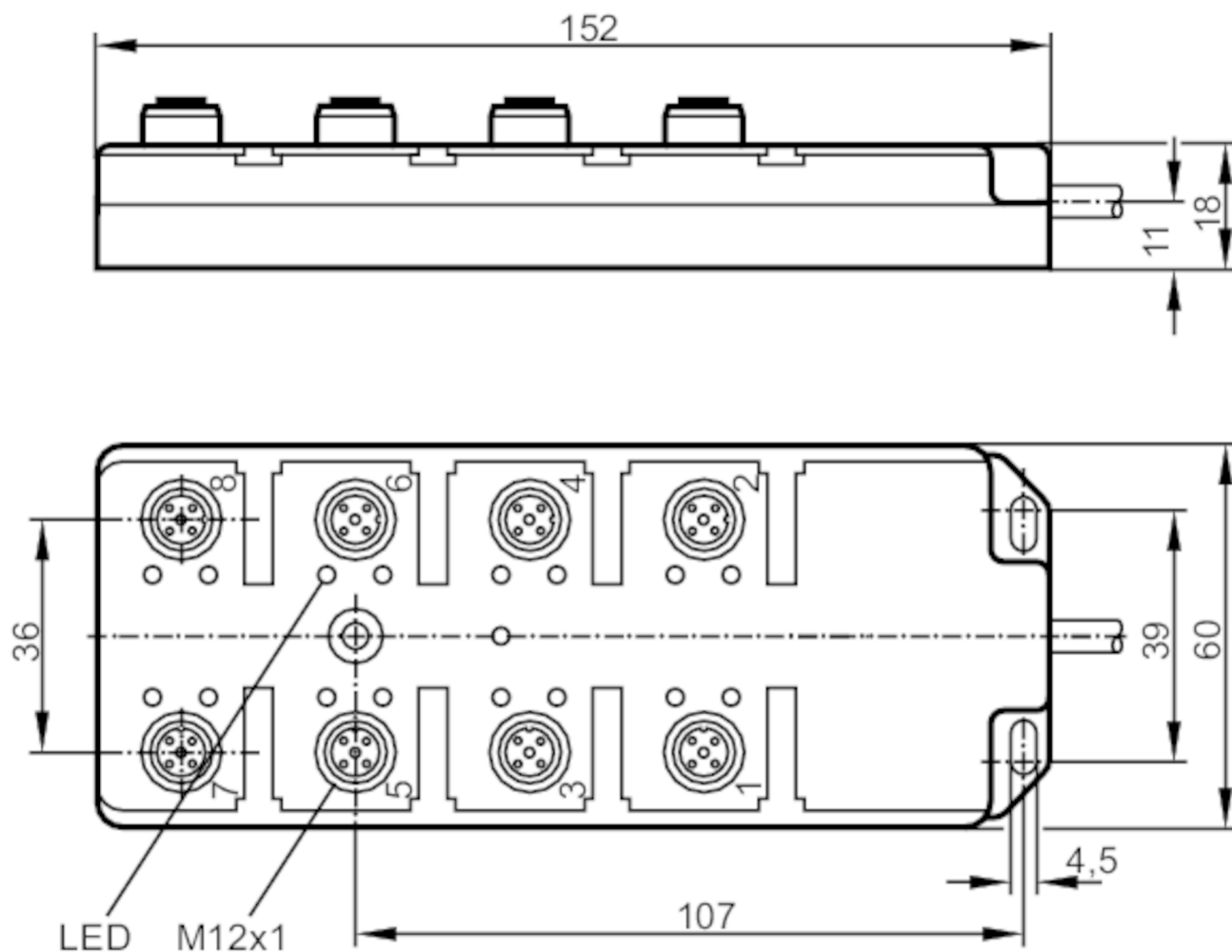

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-15...80
---------------------	------	----------

E11021



Splitter box

ZDO8H05HMSS0005H19

Protection	IP 67
------------	-------

Mechanical data

Materials	TPU
Moulded-body material	TPU
Number of ports splitter box	8
Connector type	M12

Displays / operating elements

Display	switching status	16 x LED, yellow
	operation	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

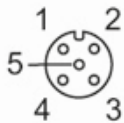


E11021



Splitter box

ZDO8H05HMSS0005H19

Connection

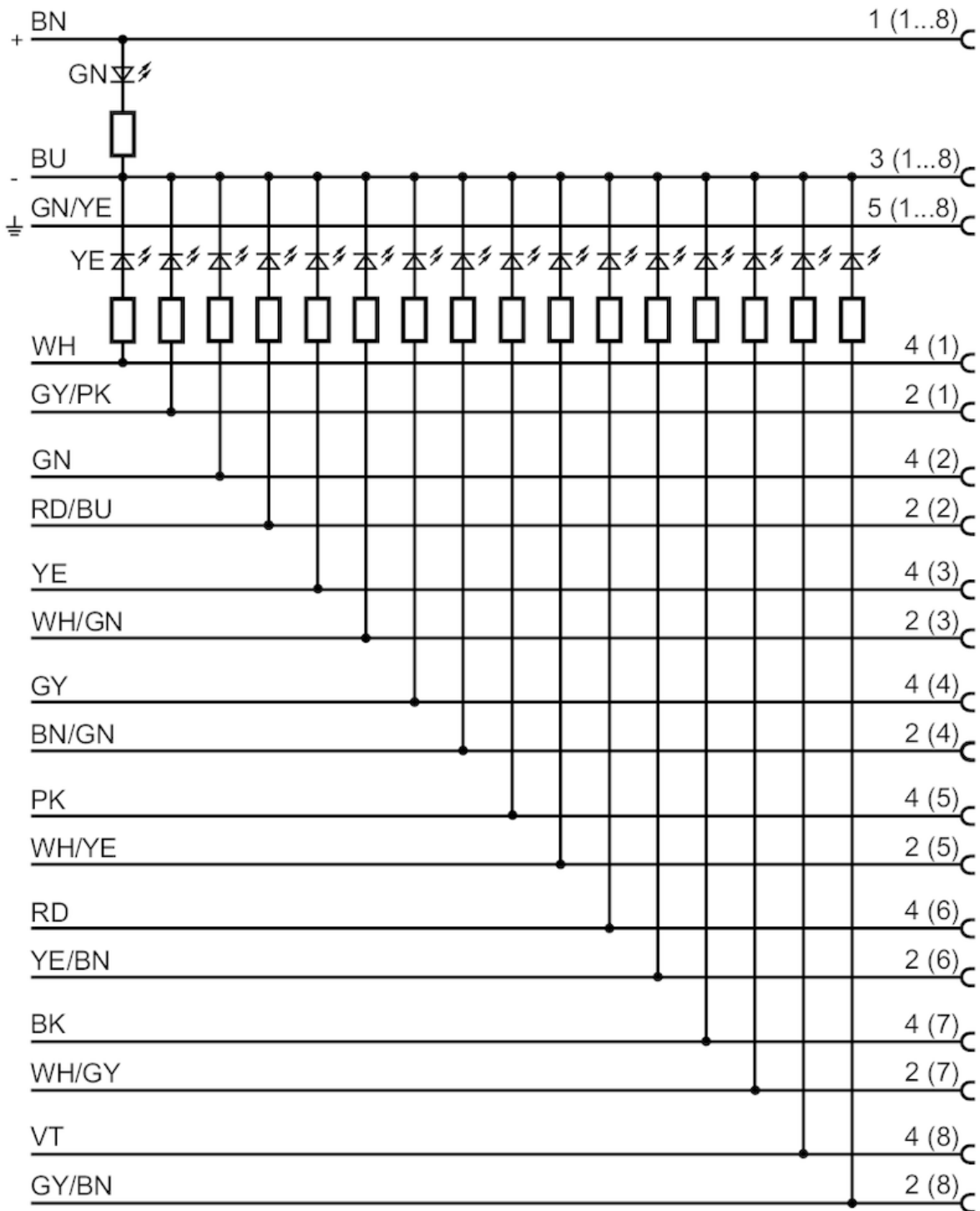

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow

E11021

Splitter box

ZDO8H05HMSS0005H19

