


E11025



Connecting cable with socket

ADOGA040VAS0010E04

Article no longer available - archive entry

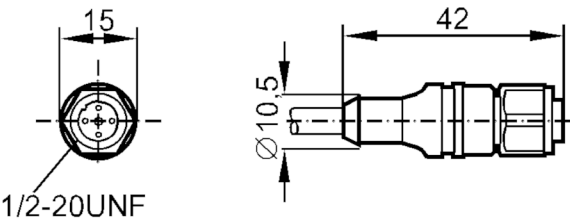

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316L/1.4404)
Remarks		
Pack quantity		1 pcs.

E11025



Connecting cable with socket


ADOGA040VAS0010E04

Electrical connection


Cable: 10 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated

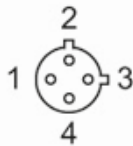

Connection

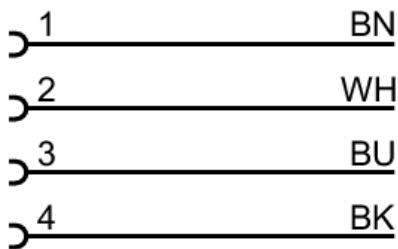

BK = Core colours :
BN = black
BU = brown
WH = blue
 white