


# E12064



## Jumper cable with valve plug

STGH050MSS0008B03VDAA041--S

Article no longer available - archive entry

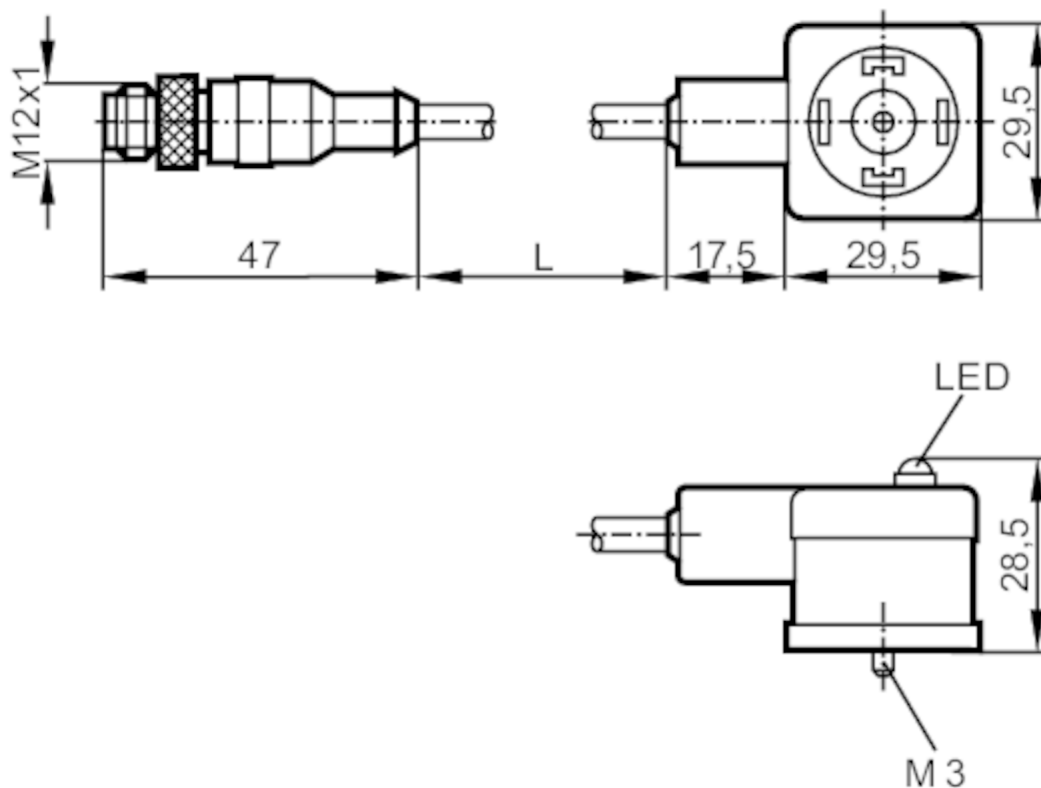

### Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes                                                    |

### Electrical data

|                        |     |                     |
|------------------------|-----|---------------------|
| Operating voltage      | [V] | < 24 AC/DC          |
| Overvoltage protection |     | free-wheeling diode |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |     |                      |
|-----------------------|-----|----------------------|
| Weight                | [g] | 400                  |
| Materials             |     | TPU                  |
| Moulded-body material |     | TPU                  |
| Material nut          |     | brass, nickel-plated |

### Displays / operating elements

|         |           |                |
|---------|-----------|----------------|
| Display | operation | 1 x LED, green |
|---------|-----------|----------------|

### Accessories

|                |                     |
|----------------|---------------------|
| Items supplied | screw               |
|                | panel for labelling |

# E12064



## Jumper cable with valve plug

STGH050MSS0008B03VDAA041--S

 
### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated



### Electrical connection

Cable: 8 m, PUR / PVC, Halogen-free; 3 x 0.5 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

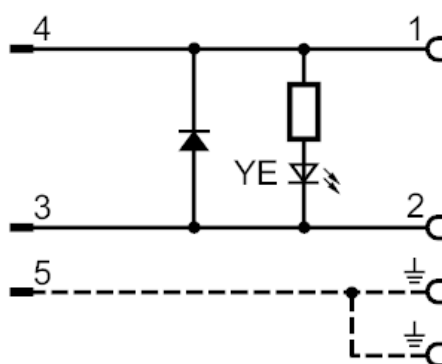

### Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: nickel-plated brass

