




Fibre optic through-beam sensor

FE-30-P-A-R6/1,2M

Article no longer available - archive entry

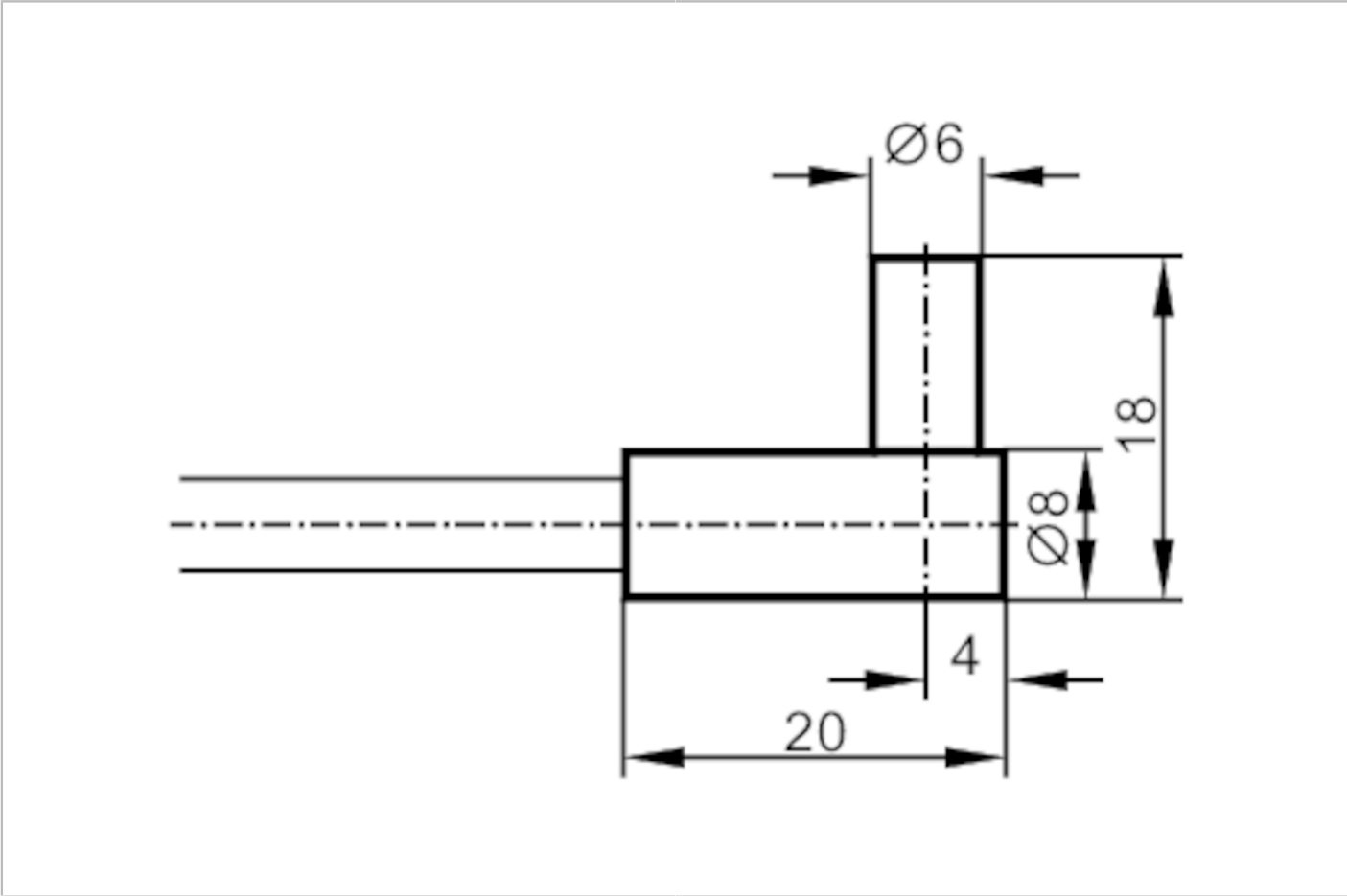

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OIF
OIF	
Range of fibre optics [mm]	288
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	angled
Total length [mm]	1200
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	Mounting clamp:, E10221

E20581



Fibre optic through-beam sensor

FE-30-P-A-R6/1,2M

Remarks	
Pack quantity	1 pcs.