


# E20054



## Fibre optic diffuse reflection sensor

FT-00-P-A-R4

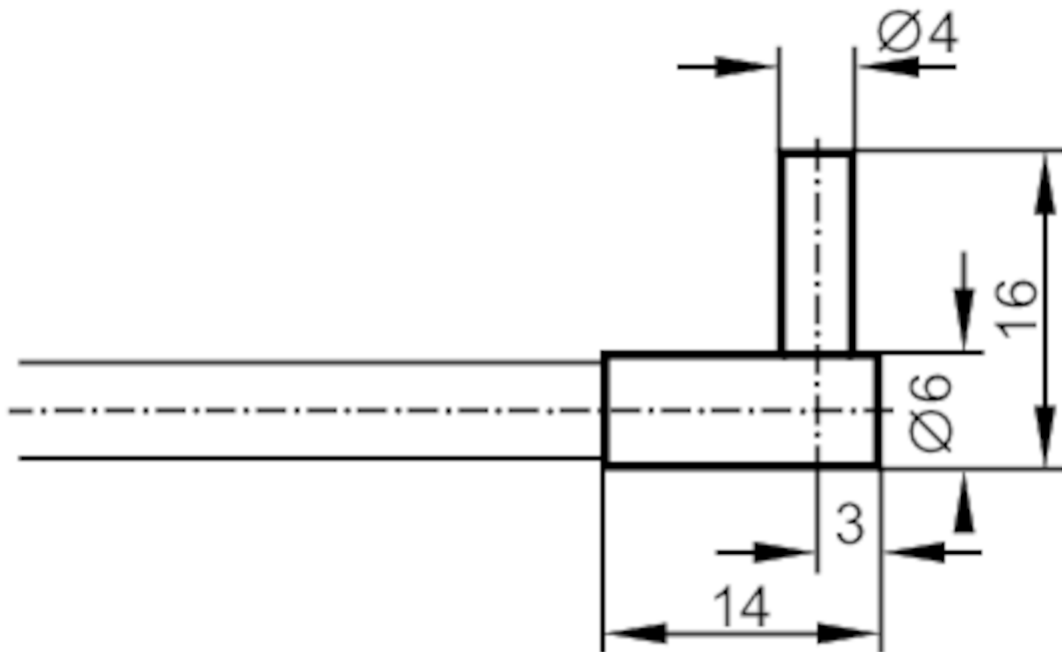

### Application

Function principle Diffuse reflection sensor

### Detection zone

Range with fibre optic amplifier type OKF; OUF; OOF

#### OKF

Range fibre optics [mm] 40

#### OOF

Range fibre optics [mm] 200

#### OUF

Range fibre optics [mm] 40

### Operating conditions

Ambient temperature [°C] -20...80

# E20054



## Fibre optic diffuse reflection sensor

FT-00-P-A-R4

Mechanical data	
Weight [g]	47
Version of sensing head	angled
Sensing head diameter [mm]	4
Sensing head length [mm]	10
Total length [mm]	600
Min. bending radius [mm]	20
Fibre arrangement	Ⓢ
Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Accessories (supplied)	E20103
Remarks	
Pack quantity	1 pcs.