


## Slot mask

SLIT DIAPHRAGM O6 1 X 8 MM

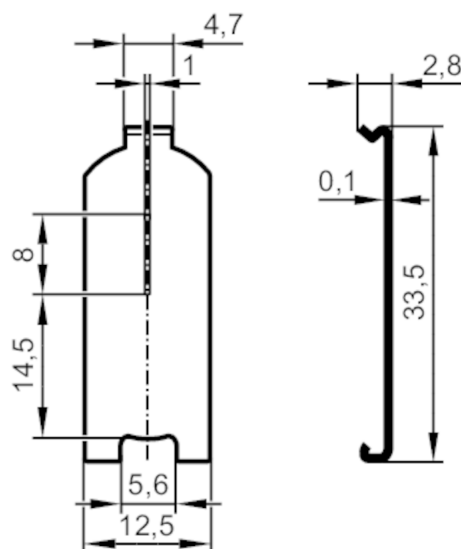

| Application                                |      |                                                                                                  |
|--------------------------------------------|------|--------------------------------------------------------------------------------------------------|
| Design                                     |      | for types O6E / O6S Kunststoff                                                                   |
| Application                                | [m]  | 1.5                                                                                              |
| Detection zone                             |      |                                                                                                  |
| Diameter of the smallest detectable object | [mm] | 0.5                                                                                              |
| Mechanical data                            |      |                                                                                                  |
| Weight                                     | [g]  | 6                                                                                                |
| Dimensions                                 | [mm] | 33.5 x 12.5 x 2.8                                                                                |
| Materials                                  |      | stainless steel (301/1.4310)                                                                     |
| Remarks                                    |      |                                                                                                  |
| Remarks                                    |      | The smallest object can only be detected if a mask is attached to both transmitter and receiver. |
| Pack quantity                              |      | 1 pcs.                                                                                           |