


E37210



Thermowell for temperature sensors

THERMOWELL, D6/1/2"NPT/L=100

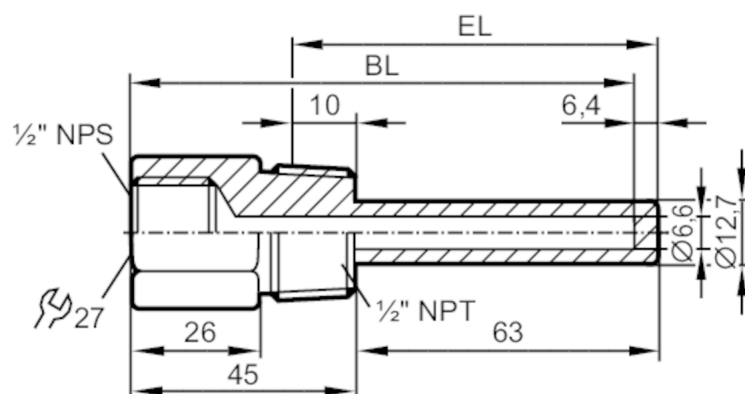

Application

Design	for temperature sensors EL = 100 mm
Pressure rating [bar]	400

Accuracy / deviations

Max. permissible flow velocity [m/s]	45
--------------------------------------	----

Mechanical data

Weight	[g]	180.5
Materials		stainless steel (316L/1.4404)
Sensor connection		1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT
Process connection		1/2" NPT
Installation length EL	[mm]	74
Bore length BL	[mm]	101.6

Remarks

Pack quantity	1 pcs.
---------------	--------