




Connection cable

VDOAF030MSS00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11381
When selecting an alternative article and accessories please note that technical data may differ!

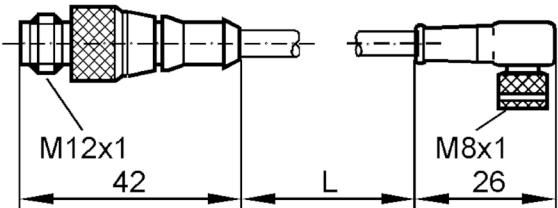

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data


Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

 Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E70023



Connection cable

VDOAF030MSS00,3A03STGH030MSS

Electrical connection

Cable: 0.3 m, PUR / PVC, orange, Ø 4.5 mm; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

