


Lower part for AS-Interface module

EMC-ROD

Article no longer available - archive entry

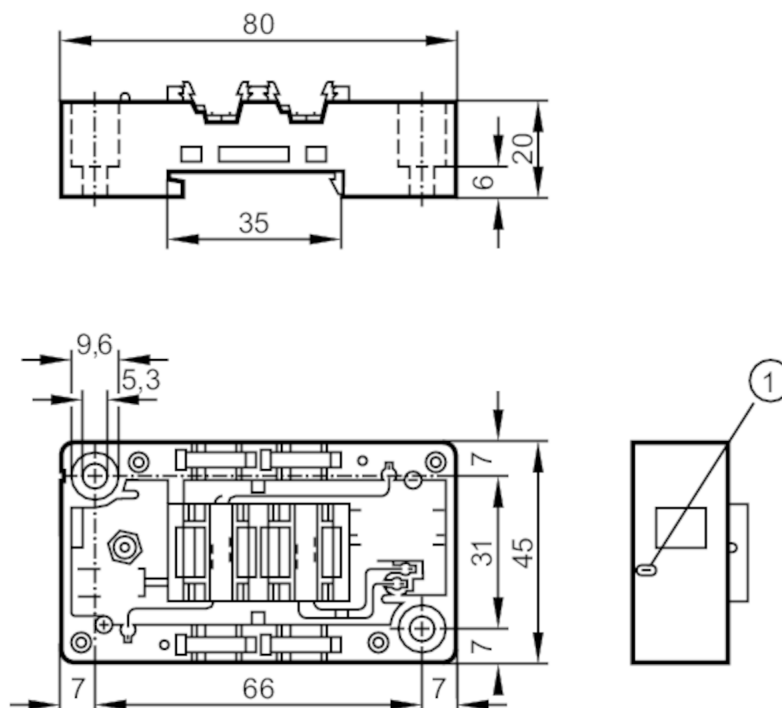

1 earthing lead



Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)

Tests / approvals

EMC	EN 50295	
	IEC 61000-4-2	
	IEC 61000-6-2	
	IEC 61643-21	

Mechanical data

Weight	[g]	69.5
Housing		mounting on DIN rail and panel
Dimensions	[mm]	45 x 80 x 20
Materials		PBT

Accessories

Items supplied	connector for the ground connection
Accessories (optional)	cover, for AS-i module, AC3000



Lower part for AS-Interface module

EMC-ROD

Remarks

Remarks

Das EMV-Unterteil dient dem Schutz der AS-i Leitung und des Oberteils durch Ableitung hoher statischer Aufladungen oder Überspannungen.


Einsetzbar nach dem Blitzschutzkonzept an den Schnittstellen OB -2 oder höher.

Pack quantity

1 pcs.

Electrical connection

Connection

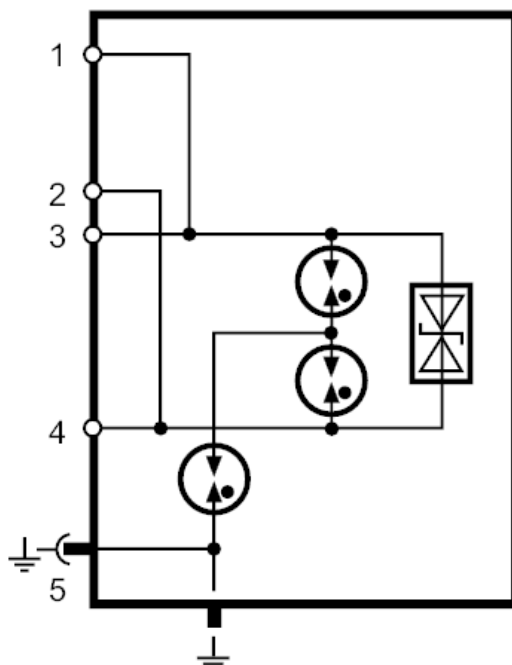

1	AS-i +
2	AS-i -
3	AS-i +
4	AS-i -
5	grounding