


## Connection cable for the connection of safety light curtains

ADAPTER CABLE RECEIVER AUTO



| Application                 |   |
|-----------------------------|---|
| Special feature             | Free from silicone; Halogen-free; Gold-plated contacts                                    |
| Design                      | For the connection of safety light curtains / safety light grids with OSSD, for receivers |
| Application                 | configured for automatic operation  |
| Free from silicone          | yes   |
| Electrical data             |   |
| Operating voltage [V]       | < 36 DC   |
| Protection class            | II  |
| Max. current load total [A] | 4; (...40 °C)   |
| Operating conditions        |   |
| Protection                  | IP 67   |
| Mechanical data             |   |
| Weight [g]                  | 47  |
| Materials                   | TPU orange; PA  |
| Moulded-body material       | TPU / PA  |
| Material nut                | brass, nickel-plated  |
| Remarks                     |   |
| Pack quantity               | 1 pcs.  |

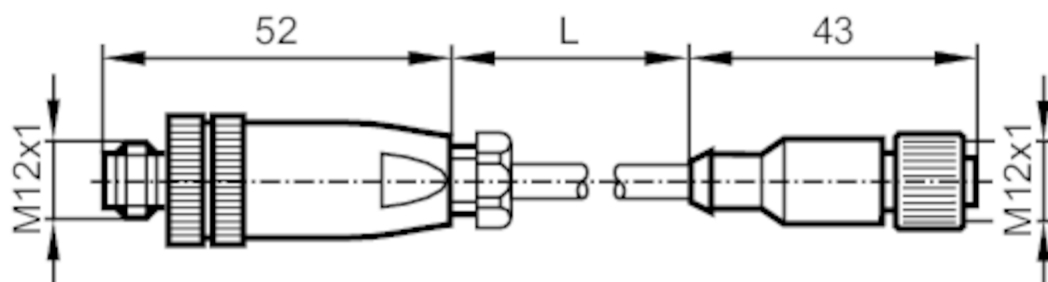

## Connection cable for the connection of safety light curtains


ADAPTER CABLE RECEIVER AUTO

### Electrical connection


Cable: 0.1 m, PUR, Halogen-free, black, Ø 4.9 mm; 5 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PA, orange; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

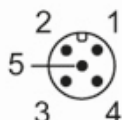

### Connection

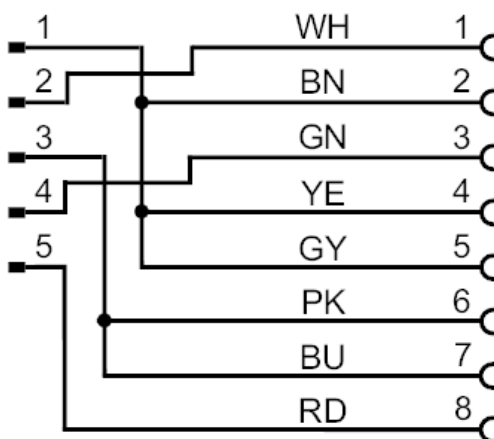

Core colours :  
 BN = brown  
 BU = blue  
 GN = green  
 GY = grey  
 PK = pink  
 RD = red  
 WH = white  
 YE = yellow

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PA, orange; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

