


Airflow monitor

SLG23XEE40KG/2M

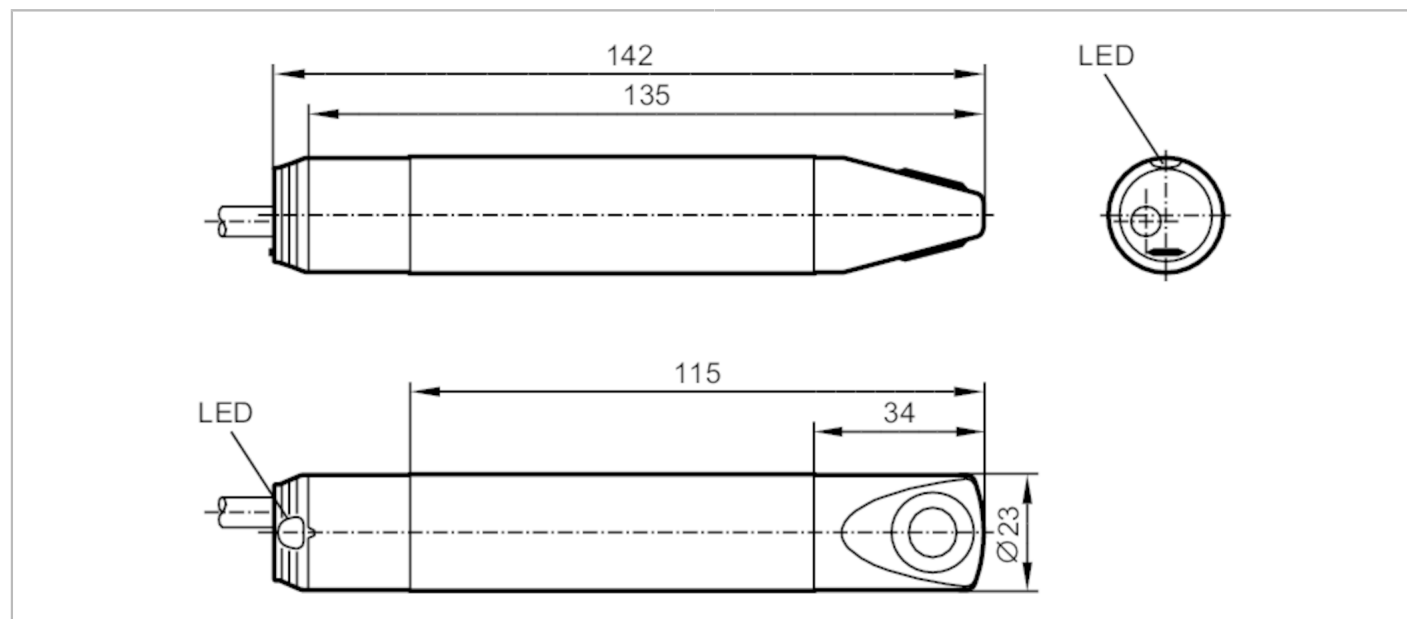

Product characteristics

Number of inputs and outputs	Number of analogue outputs: 1
Process connection	Ø 23 mm

Application

Medium temperature	[°C]	20...40
Pressure rating	[bar]	1

Electrical data

Operating voltage tolerance	[%]	-10...10
Operating voltage	[V]	24 DC
Current consumption	[mA]	< 35
Min. insulation resistance	[MΩ]	100; (500 V DC)
Power-on delay time	[s]	90

Inputs / outputs

Number of inputs and outputs	Number of analogue outputs: 1
------------------------------	-------------------------------

Outputs

Total number of outputs	1
Output signal	analogue signal
Number of analogue outputs	1
Analogue voltage output [V]	0...10

Measuring/setting range

Flow range	[cm/s]	200...3000
Note on flow range		= 1...10 V

Accuracy / deviations

Temperature gradient	[K/min]	1
----------------------	---------	---

Operating conditions

Ambient temperature	[°C]	-10...40
---------------------	------	----------

SL5204



Airflow monitor

SLG23XEE40KG/2M

Storage temperature	[°C]	-25...85
Protection		IP 65

Tests / approvals

MTTF	[years]	727
------	---------	-----

Mechanical data

Weight	[g]	195
Dimensions	[mm]	Ø 23 / L = 142
Materials		housing: PBT; sensor surface: titanium
Materials (wetted parts)		PBT; titanium
Process connection		Ø 23 mm

Displays / operating elements

Display	operation	LED, green
---------	-----------	------------

Accessories

Items supplied	Mounting clamp: 1, E40048
----------------	---------------------------


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 2 m, PUR; 4 x 0.5 mm², PVC

Connection

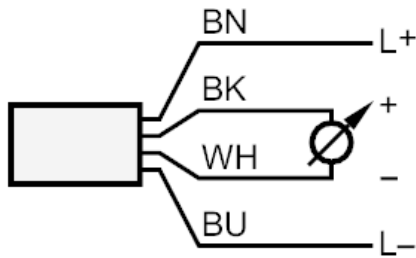

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white