


EBT005



Splitter box

ZDO8H050VAS000---KA

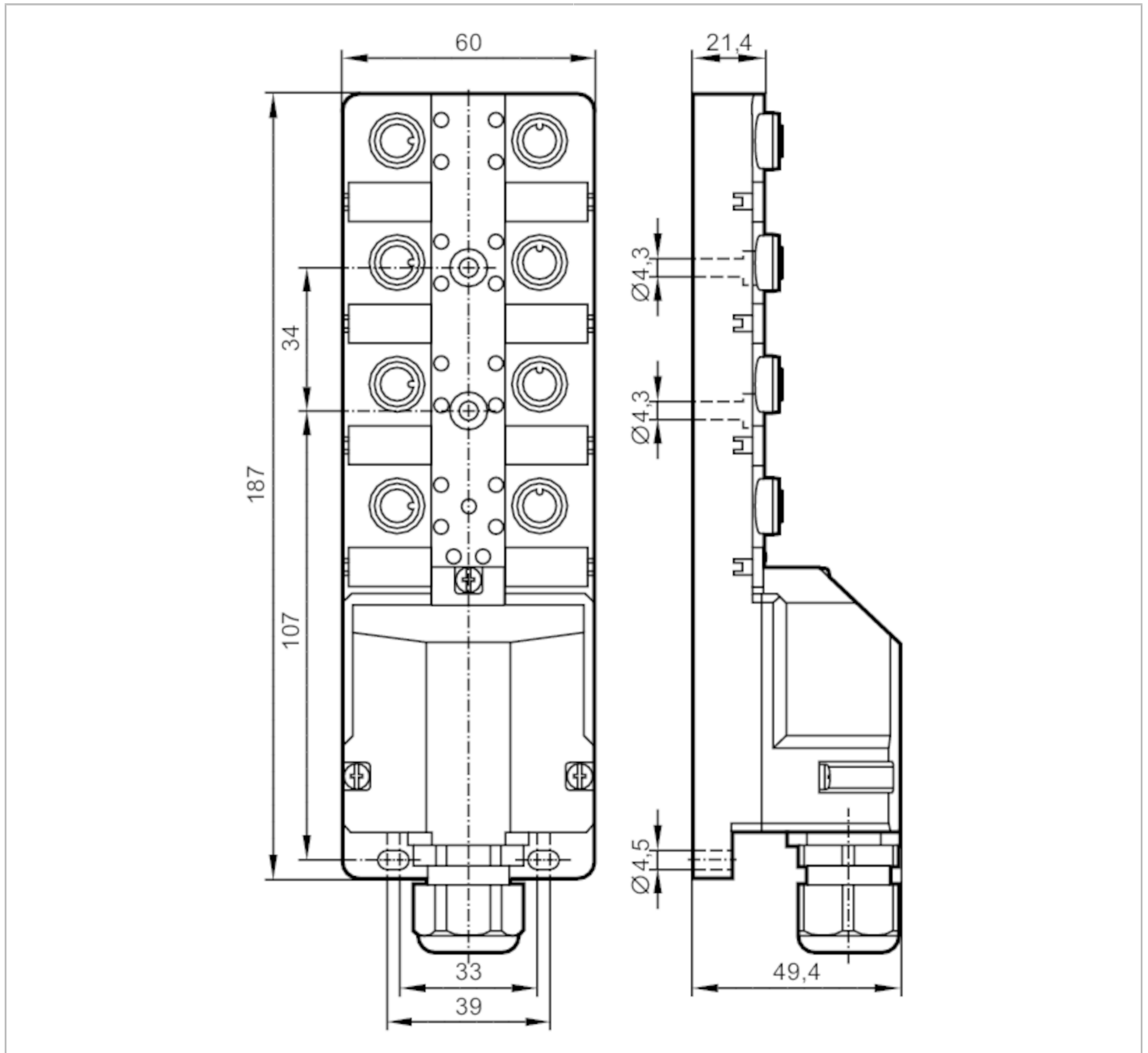

Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	10...30 DC
Max. current load per module/slot [A]	2
Max. current load total [A]	12
Outputs	
Electrical design	PNP


EBT005



Splitter box

ZDO8H050VAS000---KA

Operating conditions	
Ambient temperature	[°C] -25...80
Ambient temperature (moving)	[°C] -5...60
Protection	IP 67
Mechanical data	
Weight	[g] 404.5
Dimensions	[mm] 49.4 x 60 x 187
Materials	housing: PBT-GF30
Number of ports splitter box	8
Connector type	M12
Accessories	
Accessories (supplied)	Protective caps: 2 labels: 10 assembly tool for cage clamps
Remarks	
Pack quantity	1 pcs.
Electrical connection - Connection	
terminals: 19 x ; Cable gland: PG11	
Connector: 1 x M12; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm	

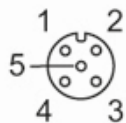


EBT005



Splitter box

ZDO8H050VAS000---KA

Connection

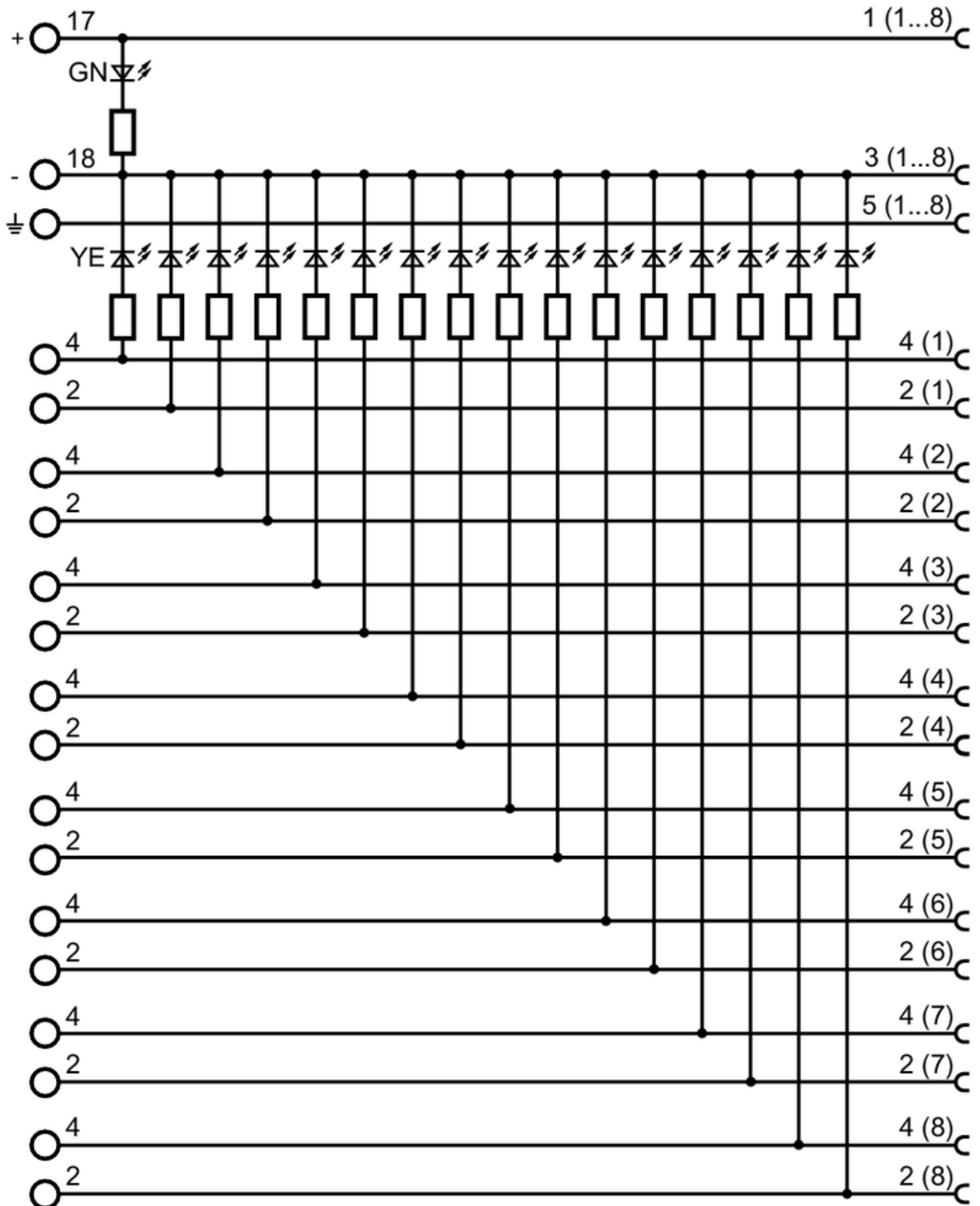

EBT005



Splitter box

ZDO8H050VAS000--KA

Electrical connection - slot

Connector: 8 x M12; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm