


Y connection cable

YDOAHXX0MSS0,25HXXSTGH050MSS

Please see the technical note under "Downloads"

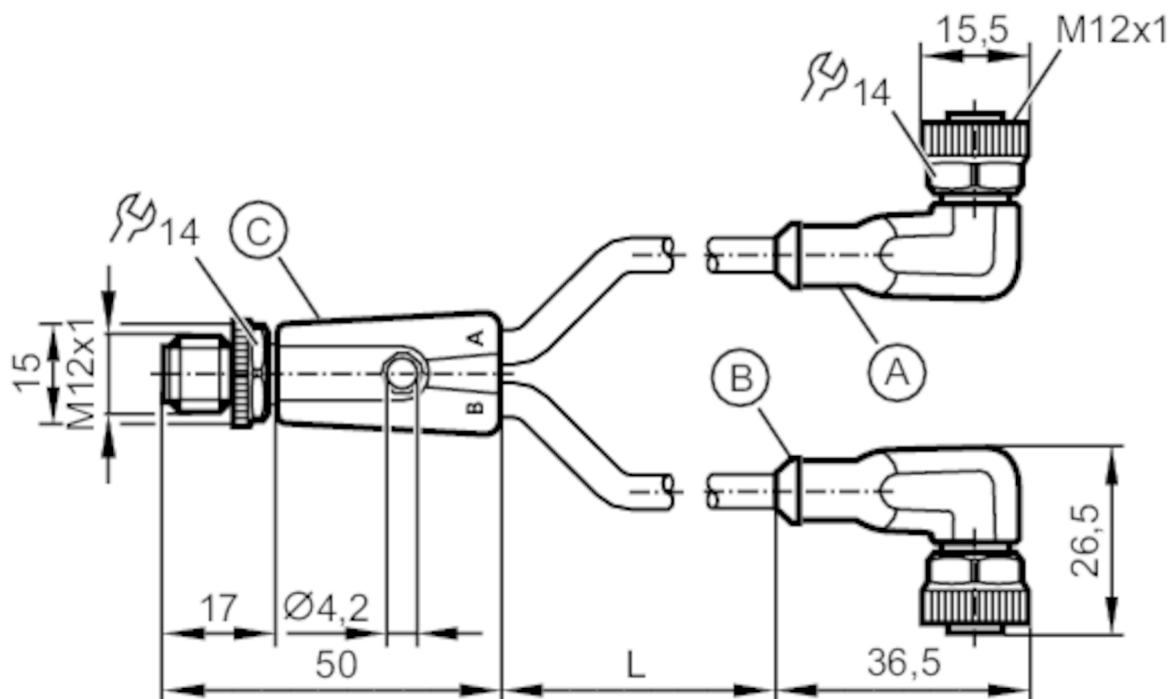

A - input cable grey
 C: octavis cable black
 B -



Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage [V]	10...30 DC
Protection class	II
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 65; IP 67; IP 68; IP 69K

Mechanical data

Weight [g]	64.7
Moulded-body material	TPU
Material nut	brass, nickel-plated
Sealing material	FKM
Number of ports splitter box	2
Drag chain suitability	yes



Y connection cable

YDOAHXX0MSS0,25HXXSTGH050MSS

Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	bending cycles	> 2 Mio.
	torsional strain	± 180 °/m

Remarks

Notes

Please see the technical note under "Downloads"

Pack quantity


1 pcs.

Electrical connection


Cable: 0.25 m, PUR, Halogen-free, grey/black, Ø 4.6 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

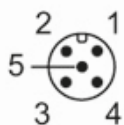

Connection

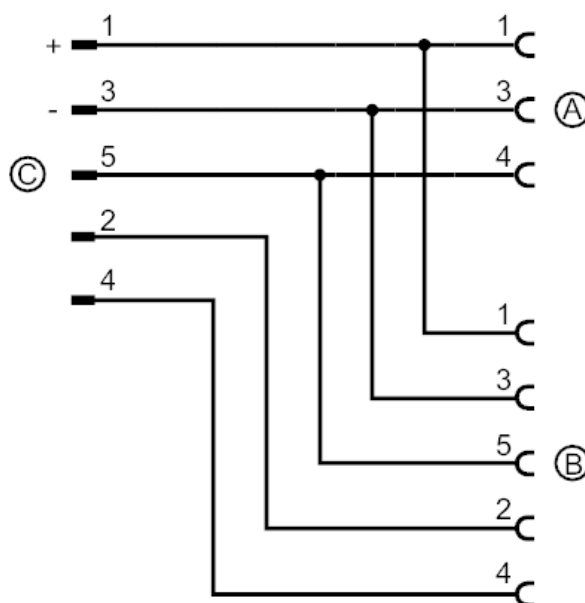

EVC503



Y connection cable

YDOAHXX0MSS0,25HXXSTGH050MSS

Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Sealing: FKM; Contacts: gold-plated;
Tightening torque: 0.6...1.5 Nm

