


# ANT860

## RFID-UHF-antenne

DTRUHFE\_AGRWKOTN04

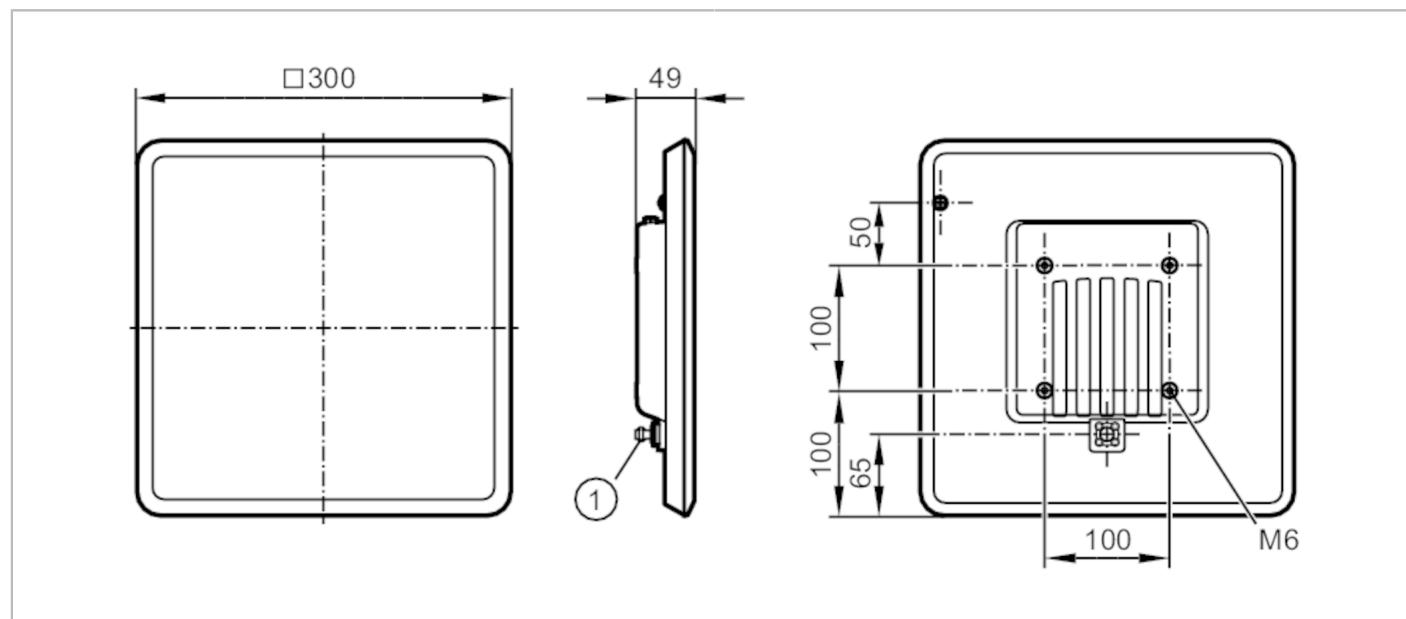

### Elektrische eigenschappen

|                          |       |                                          |
|--------------------------|-------|------------------------------------------|
| Zendfrequentie           | [MHz] | 865...868 (ETSI); (India: 865...867 MHz) |
| Antenne aansluiting      |       | 1; (TNC stekker)                         |
| Polarisatie              |       | circulaire                               |
| Zendvermogen ERP         | [mW]  | 1995                                     |
| Directiviteitsverhouding | [dB]  | 8,5                                      |
| Impedantie               | [Ω]   | 50                                       |

### Bereik

|              |     |    |
|--------------|-----|----|
| Openingshoek | [°] | 65 |
|--------------|-----|----|

### Omgevingsvariabelen

|                      |      |          |
|----------------------|------|----------|
| Omgevingstemperatuur | [°C] | -40...70 |
| Opslagtemperatuur    | [°C] | -40...85 |
| Beschermklasse       |      | IP 67    |

### Mechanische eigenschappen

|            |      |                                                                            |
|------------|------|----------------------------------------------------------------------------|
| Gewicht    | [g]  | 2395,5                                                                     |
| Behuizing  |      | rechthoekig                                                                |
| Afmetingen | [mm] | 300 x 300 x 79                                                             |
| Materialen |      | behuizing: aluminium; TNC stekker: Messing / PTFE; Beschermkap: kunststof; |

### Opmerkingen

|                    |  |        |
|--------------------|--|--------|
| Verpakkingseenheid |  | 1 stuk |
|--------------------|--|--------|