


IG-3008-BPKG/10M

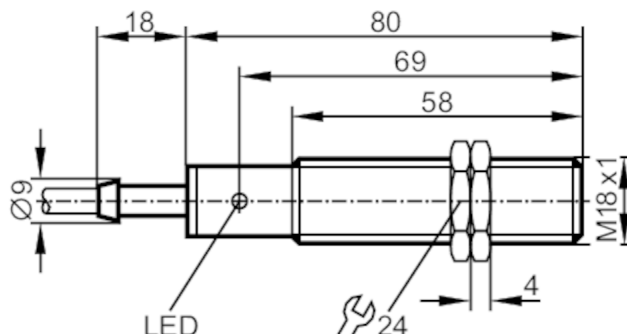

PNP

maakcontact

8

cilindrisch schroefdraad

M18 x 1 / L = 80

[M]

10...36 DC

[mA]

15; (24 V)

11

ja

PNP

maakcontact

[M]

2,5

[mA]

250

[Hz]

300

ja

pulserend

ja

[mm]

8

[mm]

 $8 \pm 10 \%$

[mm]

0...6,5

staal: 1 / roestvast staal: 0,7 / messing: 0,4 / aluminium: 0,3 / koper: 0,2

[% van Sr]

1...15

[% van Sr]

-10...10



Inductieve sensor

IG-3008-BPKG/10M

Omgevingsvariabelen		
Omgevingstemperatuur	[°C]	-25...80
Beschermklasse		IP 67
Toelatingen / testen		
EMC	EN 60947-5-2	
MTTF	[jaren]	1853
Mechanische eigenschappen		
Gewicht	[g]	490
Behuizing		cilindrisch schroefdraad
Inbouwwijze		niet-bondig in te bouwen
Afmetingen	[mm]	M18 x 1 / L = 80
Schroefdraadtype		M18 x 1
Materialen		PBT
Aanwijzen / bedienelementen		
Weergave	schakelstatus	1 x LED, geel
Toebehoren		
Leveringsomvang		bevestigingsmoeren: 2
Opmerkingen		
Verpakkingseenheid		1 stuk
Elektrische aansluiting		
Kabel: 10 m, PVC; 3 x 0,5 mm ²		
Aansluiting		



Aderkleuren :

BN = bruin

BU = blauw

BK = zwart