


E3R100



Forbindelseskabel

HFM Y CABLE 2 X S/S/M S/D/M A 2,0M

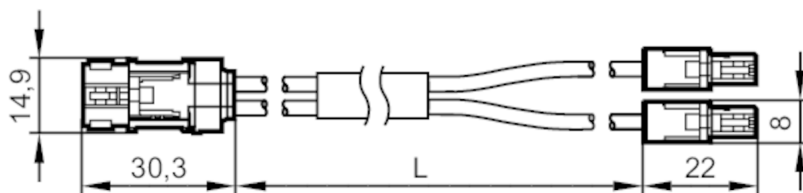

Elektriske data

Driftsspenning [V]	< 50,00 AC / < 60,00 DC
Beskyttelsesklasse	III
Demping [dB/m]	1,60
Indre motstand (Ri) [Ω]	50,00; (± 3 %)

Driftsforhold

Omgivelsestemperatur [°C]	-10,00...60,00
Omgivelsestemperatur (drivende) [°C]	-10,00...60,00
Beskyttelse	IP 54

Mekaniske data

Vekt [g]	91,62
Liten bøyeradius [mm]	16,50; (separat; 15 x 3,3 mm min. 10 x kabeldiameter)
Materialer	hus: : PBT-GF20

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

Elektrisk tilkobling - 2D/3D-kamera

Koblinger: 1 x HFM-Dual, rett

Elektrisk tilkobling

Kabel: 2 m, svart, Ø 3,3 mm

Elektrisk tilkobling - Video Processing Unit

Koblinger: 2 x HFM-Single, rett