



E10136

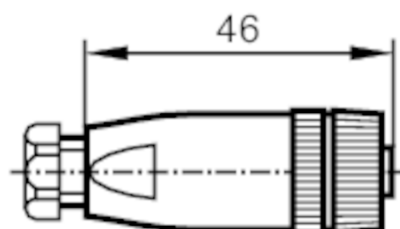

Kabelkompatibelt støpsel

SDOGH042PLSFKPG

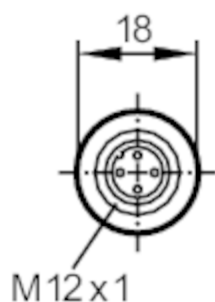

Elektriske data

Driftsspenning	[V]	10,00...30,00 DC
----------------	-----	------------------

Utganger

Elektrisk design	PNP
------------------	-----

Driftsforhold

Omgivelsestemperatur	[°C]	-40,00...85,00
Beskyttelse		IP 67

Mekaniske data

Vekt	[g]	14,00
Dimensjoner	[mm]	18,00 x 18,00 x 46,00
Materialer		PA
Støpt kroppsmateriale		PA
Materiale mutter		PA

Displayer/driftselementer

Display	koblingsstatus	1 x LED, gul
	drift	1 x LED, grønn

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

E10136



Kabelkompatibelt støpsel

SDOGH042PLSFKPG

Elektrisk tilkobling

skrueterminaler: ...0,75 mm²; Kabelskjede: Ø 4...6 mm

Elektrisk tilkobling - Stikkontakter

Koblinger: 1 x M12, rett; koding: A; Støpt kropp: PA; låse: PA



Tilkobling

