


E10137



Kabelkompatibelt støpsel

SDOGJ040PLSFKPG

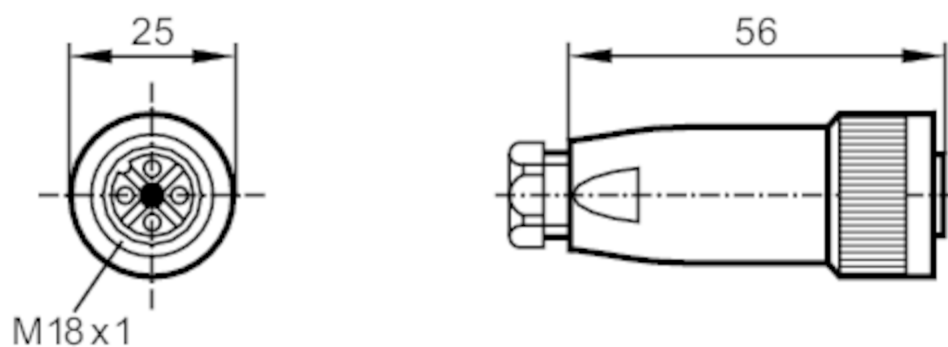

Elektriske data

Driftsspenning	[V]	< 250,00 AC/DC
Maks. nåværende belastning totalt	[A]	4,00; (...40 °C)

Driftsforhold

Omgivelsestemperatur	[°C]	-40,00...85,00
Beskyttelse		IP 65

Mekaniske data

Vekt	[g]	26,60
Dimensjoner	[mm]	25,00 x 25,00 x 56,00
Materialer		PA
Støpt kroppsmateriale		PA
Materiale mutter		ULTRAMID

Merknader

Antall i forpakning		1,00 stk.
---------------------	--	-----------

E10137



Kabelkompatibelt støpsel

SDOGJ040PLSFKPG

Elektrisk tilkobling

terminaler: ...0,75 mm²; Kabelskjede: Ø 6...8 mm

Elektrisk tilkobling - Stikkontakter

Koblinger: 1 x M18, rett; koding: A; Støpt kropp: PA; låse: ULTRAMID



Tilkobling

