


Overgangsplugg

ESTGH040MSS0,08E04 (M16)

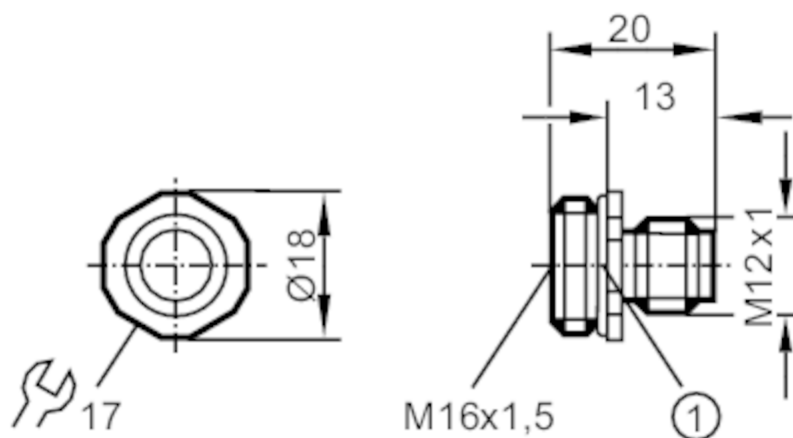

1 O-ring



Elektriske data

Driftsspenning	[V]	< 250,00 AC/DC
----------------	-----	----------------

Driftsforhold

Omgivelsestemperatur	[°C]	-25,00...85,00
----------------------	------	----------------

Beskyttelse	IP 68
-------------	-------

Mekaniske data

Vekt	[g]	30,74
------	-----	-------

Monteringsgjenger	M16 x 1,5
-------------------	-----------

Materialer	diecast zinc forniklet
------------	------------------------

Støpt kroppsmateriale	diecast zinc, forniklet
-----------------------	-------------------------

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

E11528



Overgangsplugg

ESTGH040MSS0,08E04 (M16)

Elektrisk tilkobling

Kabel: 0,08 m, PVC; 4 x 0,34 mm²

Elektrisk tilkobling - koble

Koblinger: 1 x M12, rett; koding: A; Støpt kropp: diecast zinc, forniklet



Tilkobling

1	BN
2	WH
3	BU
4	BK

BK = Lederfarger :
BN = svart
BU = brun
WH = blå
 hvit