


Adapterkontakt

EDOGH050MSS00,7E05(M16)

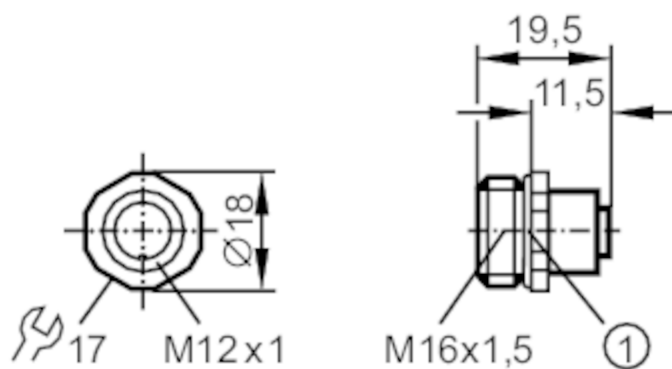

1 O-ring



Elektriske data

Driftsspenning	[V]	< 125,00 AC/DC
----------------	-----	----------------

Driftsforhold

Omgivelsestemperatur	[°C]	-25,00...85,00
Beskyttelse		IP 68

Mekaniske data

Vekt	[g]	25,10
Monteringsgjenger		M16
Materialer		diecast zinc forniklet
Støpt kroppsmateriale		diecast zinc, forniklet

Merknader

Antall i forpakning		1,00 stk.
---------------------	--	-----------

E11917



Adapterkontakt


EDOGH050MSS00,7E05(M16)

Elektrisk tilkobling


Kabel: 0,7 m, PVC; 4 x 0,25 mm² + 1 x 0,5 mm²

Elektrisk tilkobling - Stikkontakter

Koblinger: 1 x M12; koding: A; Støpt kropp: diecast zinc, forniklet

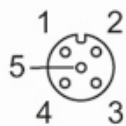

Tilkobling

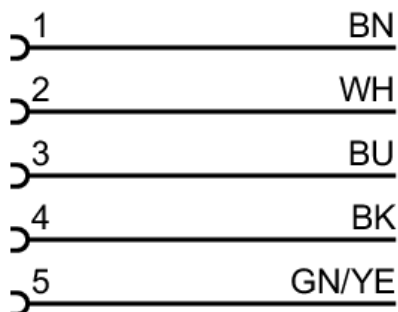

BK =	Lederfarger :
BN =	svart
BU =	brun
GN/YE =	blå
WH =	grønn/gul
	hvit